


- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e


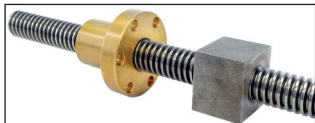


Uses

- Machine tools
- Lathe main screw

Options

- Available in lengths up to 6000mm (for diameters 30mm or greater)

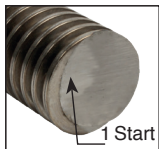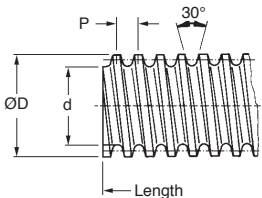

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	List	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS


Qté	1+	5+	10+
Rem.	List	-5%	On request
Lngt.	1000	2000	3000 6000 mm
Price	Uni.	x2,12	x3,18 On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	40 to 59**
LFM102	10	2	6,89	0,46	✓	7,73 €	4.64
LFM123	12	3	07,68	0,65	✓	10,97 €	6.58
LFM143	14	3	09,68	0,93	✓	14,13 €	8.48
LFM164	16	4	10,47	1,15	✓	17,46 €	10.48
LFM184	18	4	12,47	1,52	✓	21,53 €	12.92
LFM204	20	4	14,47	1,91	✓	25,80 €	15.48
LFM225	22	5	15,29	2,30	✓	30,93 €	18.56
LFM245	24	5	17,27	2,80	✓	35,50 €	21.30
LFM285	28	5	21,27	3,90	✓	49,22 €	29.53
LFM306	30	6	21,56	4,33	✓	53,84 €	32.30
LFM326	32	6	23,56	5,00	✓	61,57 €	36.94
LFM366	36	6	27,56	6,55	✓	46,16 €	On request
LFM407	40	7	30,38	8,00	✓	58,30 €	On request
LFM447	44	7	34,38	9,86	✓	77,09 €	On request
LFM508	50	8	39,17	12,76	✓	95,92 €	On request
LFM609	60	9	47,98	18,65	-	137,79 €	On request
LFM7010	70	10	56,82	25,65	-	188,06 €	On request
LFM8010	80	10	66,82	34,21	-	264,14 €	On request
LFM9012	90	12	74,44	43,00	-	402,70 €	On request
LFM9516	95	16	73,71	45,60	-	392,57 €	On request
LFM10016	100	16	78,71	51,00	-	441,94 €	On request
LFM12016	120	16	98,71	76,00	-	645,20 €	On request

*Depending on availability - Dimensions in mm

** refer to discounts

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e


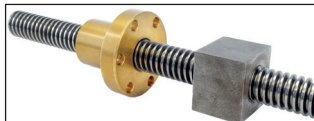


Uses

- Machine tools
- Lathe main screw

Options

- Available in lengths up to 6000mm (for diameters 30mm or greater)

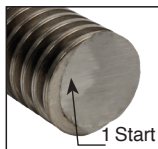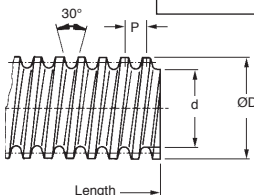

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qté	1+	5+	10+	
Rem.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	40 to 59**
LFM102/LH	10	2	6,89	0,46	✓	9,52 €	5,71
LFM123/LH	12	3	07,68	0,65	✓	13,57 €	8,14
LFM143/LH	14	3	09,68	0,93	✓	18,58 €	11,15
LFM164/LH	16	4	10,47	1,15	✓	21,10 €	12,66
LFM184/LH	18	4	12,47	1,52	✓	25,92 €	15,55
LFM204/LH	20	4	14,47	1,91	✓	29,48 €	17,69
LFM225/LH	22	5	15,29	2,30	✓	36,57 €	21,94
LFM245/LH	24	5	17,27	2,80	✓	39,05 €	23,43
LFM285/LH	28	5	21,27	3,90	✓	57,77 €	34,66
LFM306/LH	30	6	21,56	4,33	✓	60,62 €	36,37
LFM326/LH	32	6	23,56	5,00	✓	70,33 €	42,20
LFM366/LH	36	6	27,56	6,55	-	52,29 €	On request
LFM407/LH	40	7	30,38	8,00	-	71,95 €	On request
LFM447/LH	44	7	34,38	9,86	-	102,22 €	On request
LFM508/LH	50	8	39,17	12,76	-	117,32 €	On request
LFM559/LH	55	9	42,98	15,40	-	On request	On request
LFM609/LH	60	9	47,98	18,65	-	178,92 €	On request
LFM7010/LH	70	10	56,82	25,65	-	243,97 €	On request
LFM8010/LH	80	10	66,82	34,21	-	354,53 €	On request
LFM9012/LH	90	12	74,44	43,00	-	On request	On request
LFM9516/LH	95	16	73,71	45,60	-	On request	On request
LFM10016/LH	100	16	78,71	51,00	-	On request	On request
LFM12016/LH	120	16	98,71	76,00	-	On request	On request

*Depending on availability - Dimensions in mm


** refer to discounts

Our other products



PM3

 Worm and wheel set,
Hardened steel



CFC

Spring loaded position
switch, Electric
contact



PCLA_M

Technopolymer
clamping lever -
female, Plastic



 
FUSS

Bearing locknut, Self
locking locknut -
stainless steel lock
washer



BFA

Shaft locking washer,
E clip



H3

Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)




CAP805

Slat top chain
stainless steel, Large
range 805



EHD04

 Internal epicyclic
servo reducers, from
3.4 to 7 Nm



BLHM20

Right angled gearbox,
double output shafts,




BL15

Right angled gearbox,
from 1.10 to 6 Nm



CF

 Cam follower,
Standard - steel



LAT1

1A motorised linear
actuator, 1 ampere

Complementary products



 
BFM

Flanged bronze nut,
Bronze - 1 thread



LRM

Trapezoidal bronze
nut, Bronze - 1 thread



VKM

Square steel nut,
Steel - 1 thread



SVT15

Screwjack with
travelling screw, with
translating screw