

- Cold rolled (plastic deformation)
- Conforms to DIN 103 (NFE 03-615)
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e

### Uses


- Machine tools
- Lathe main screw

### Accessories



- LRM and BFM dual thread bronze nuts
- KSM dual thread steel nuts

### Options

- Available in lengths up to 6000mm (subject to diameter)

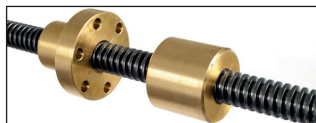

2 Starts

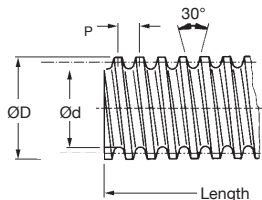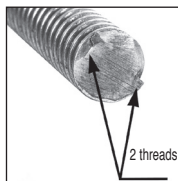

## DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Long	1000	2000	3000	6000 mm
Price	Each	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d min.	Price per metre	
				1 to 9	20 to 39**
LFM126	12	6	07,68	12,82 €	7.69
LFM146	14	6	09,68	16,42 €	9.85
LFM168	16	8	10,47	21,46 €	12.88
LFM188	18	8	12,47	30,20 €	18.12
LFM208	20	8	14,47	32,85 €	19.71
LFM2210	22	10	15,29	38,42 €	23.05
LFM2410	24	10	17,27	43,37 €	26.02
LFM2610	26	10	19,27	63,58 €	38.15
LFM2810	28	10	21,27	71,58 €	42.95
LFM3012	30	12	21,56	60,28 €	36.17
LFM3212	32	12	23,56	98,58 €	59.15
LFM3612	36	12	27,56	97,93 €	58.76
LFM4014	40	14	30,38	121,49 €	72.89

Dimensions in mm

\*\* REFER TO DISCOUNTS

## Our other products



BTC20\_10

End cap for rectangular tube, Standard



PWC

Powercoil thread inserts, Kit Powercoil - with or without insertion ...



CHB

Reaction arm, CHB gear reducers




GP

Spring loaded toggle latch, With padlock-holder



CHMR40

 Worm and wheel gear reducer, up to 57 Nm



FRss

Stainless steel thread inserts, Stainless steel



BLM

Spring loaded plunger with ball tip, Stainless steel body



PSG35

Spur gear - precision range, Stainless steel 316



MET

Cylindrical sintered bronze bush, Self-lubricating



SH3

Parallel axis helical gear, Steel 20NCD2



ACLBDB

Closing mechanism for aluminium profile,



RBG

Wheel, Grey rubber - Polypropylene rim

## Complementary products



BFM2

Flanged bronze nut, Bronze - 2 threads



LRM2

Cylindrical bronze nut, Bronze - 2 threads