


Mechanical catch

LQT

with 2 balls

- Quick closing catch
- Push to close
- Material:
Chromed zamak

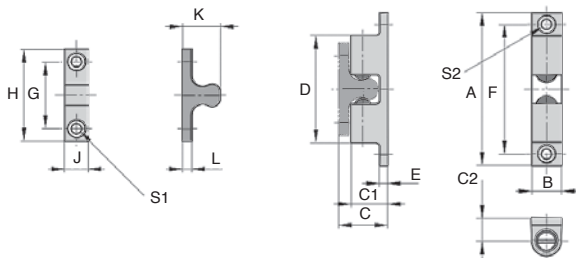

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	C1	C2	D	E	F	G
LQT-2B-42-8	42,5	8,0	14,0	10,0	6,5	26,7	2,5	35	16
LQT-2B-50-10	50,0	10,0	16,0	12,5	7,4	29,8	3,0	40	20
LQT-2B-70-13	70,0	13,5	21,2	17,0	11,0	49,0	4,0	60	30

Part number	H	J	K	L	S1	S2	Force (N)	Weight (g)	Price each 1 to 5
LQT-2B-42-8	25	7,5	11,3	2,5	3,2	6,2	30	16	12,38 €
LQT-2B-50-10	30	9,0	12,3	2,5	4,2	8,2	33	26	14,57 €
LQT-2B-70-13	42	10,5	17,2	3	4,2	8,2	35	70	25,10 €

Dimensions in mm

Our other products



Joining plate for aluminium profile, joint plate - 176x86 mm



Stainless steel hexagonal headed thumb nut, Lobed handscrew



 
T type timing belt per metre, T5 Steel cored polyurethane



Connecting plate for AT type timing belts, AT10



Warning chain with red and white links, Steel



Worm and wheel gear reducer, up to 40 Nm



Worm and wheel set, Machined plastic (delrin)



AT type timing pulley, Economy range - AT5 aluminium



Panel stop, Panel stop



Fixed levelling foot, Flanged plate



Worm and wheel set, Machined plastic (delrin)



Right angled mounting plate, Right angled mounting plate for ball jo...

Complementary products



Spring loaded latch, Spring loaded latch