


Mechanical catch

LQT

with 2 balls

- Quick closing catch
- Push to close
- Material:
Chromed zamak

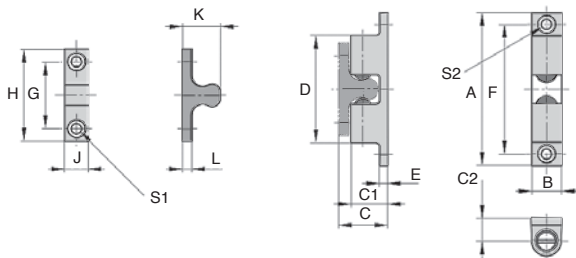

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	C1	C2	D	E	F	G
LQT-2B-42-8	42,5	8,0	14,0	10,0	6,5	26,7	2,5	35	16
LQT-2B-50-10	50,0	10,0	16,0	12,5	7,4	29,8	3,0	40	20
LQT-2B-70-13	70,0	13,5	21,2	17,0	11,0	49,0	4,0	60	30

Part number	H	J	K	L	S1	S2	Force (N)	Weight (g)	Price each 1 to 5
LQT-2B-42-8	25	7,5	11,3	2,5	3,2	6,2	30	16	12,38 €
LQT-2B-50-10	30	9,0	12,3	2,5	4,2	8,2	33	26	14,57 €
LQT-2B-70-13	42	10,5	17,2	3	4,2	8,2	35	70	25,10 €

Dimensions in mm

Our other products



 
BABreceptacle

Ball pin socket, Socket



EIM

Stainless steel U bolt,
Stainless steel



MR_MMR

Metric section rack,
Steel



VBFP

Small 6 lobe threaded
handle - female,
Duroplast - Stainless
steel



VTHA

Magnetic screw with
hexagonal head, Steel



BPP

Pressed steel flanged
bearing for light
loads, Sheet steel



COA-COG

Surface mounting
plate, Surface
mounting plate for
ball joint



RAM35

Manual bevel
gearbox, Bevel



GFX

Curved tooth
coupling, economy
range, Steel and



MET

Cylindrical sintered
bronze bush, Self-
lubricating sintered



T25-6ECO

T type timing pulley,
Economy range - T2.5
aluminium



BPFLss

Pressed stainless
steel flange bearing,
Stainless steel

Complementary products



LRR

Spring loaded latch,
Spring loaded latch