


Mechanical catch

LQT

with 2 balls

- Quick closing catch
- Push to close
- Material:
Chromed zamak

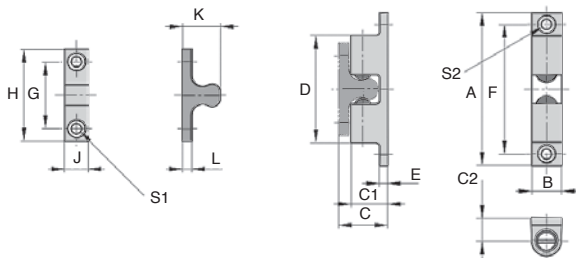

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	C1	C2	D	E	F	G
LQT-2B-42-8	42,5	8,0	14,0	10,0	6,5	26,7	2,5	35	16
LQT-2B-50-10	50,0	10,0	16,0	12,5	7,4	29,8	3,0	40	20
LQT-2B-70-13	70,0	13,5	21,2	17,0	11,0	49,0	4,0	60	30

Part number	H	J	K	L	S1	S2	Force (N)	Weight (g)	Price each 1 to 5
LQT-2B-42-8	25	7,5	11,3	2,5	3,2	6,2	30	16	12,38 €
LQT-2B-50-10	30	9,0	12,3	2,5	4,2	8,2	33	26	14,57 €
LQT-2B-70-13	42	10,5	17,2	3	4,2	8,2	35	70	25,10 €

Dimensions in mm

Our other products



PMB
Anti-vibration
machine mount, Oval
base plate



RT61ss
Self-centering locking
Assembly,
Medium/low torque



INS
Self tapping steel
insert, Steel



GE_ES
Spherical bushing,
Steel / steel



P20
Worm and wheel gear
reducer, up to 5 Nm



ACLBT5
Closing system for
aluminium profile,
Spacer for spherical
ended stop



PR40
Articulated foot Ø40,
Ø 40



GCA
Linch pin, Linch



LRR
Catch-plate for latch,
Catch-plate



ZDB
Machined plastic
bevel gear , 2:1



HW_HT
Half-rail guide, Wheel



CHAR
Spring hinge, screwed

Complementary products



LRR
Spring loaded latch,
Spring loaded latch