


Mechanical catch

LQT

with 2 balls

- Quick closing catch
- Push to close
- Material:
Chromed zamak

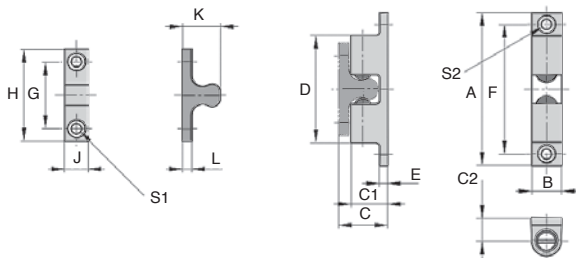

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	C1	C2	D	E	F	G
LQT-2B-42-8	42,5	8,0	14,0	10,0	6,5	26,7	2,5	35	16
LQT-2B-50-10	50,0	10,0	16,0	12,5	7,4	29,8	3,0	40	20
LQT-2B-70-13	70,0	13,5	21,2	17,0	11,0	49,0	4,0	60	30

Part number	H	J	K	L	S1	S2	Force (N)	Weight (g)	Price each 1 to 5
LQT-2B-42-8	25	7,5	11,3	2,5	3,2	6,2	30	16	12,38 €
LQT-2B-50-10	30	9,0	12,3	2,5	4,2	8,2	33	26	14,57 €
LQT-2B-70-13	42	10,5	17,2	3	4,2	8,2	35	70	25,10 €

Dimensions in mm

Our other products



HTD5M_25

HTD-type pulley for RPP-type belt, HTD5 Aluminium



DG0

Double spur gear, Stainless steel 303



HLUss

Hand wheel, Stainless steel 316



AT5M AT10M

Timing belt per metre, AT10 Steel cored polyurethane



CHA138

Screw-in hinge, 138 degrees



IN1

Internal gear, Steel 20NCD2



BAGSS

Clamping ring, Stainless steel



LVT

Miniature motorised actuator, 1 amper



PRS30

Articulated foot, Ø 30



FGWA

Shaft end support, With base



PTAF80-PAMF80

Articulated fixable foot with pressed base, Ø 80



CLLCLLP

Trunnion, Steel - long version

Complementary products



LRR

Latch, Spring loaded latch