

LRH 1 right hand start, 1 left hand start

- Lead screw with 1 right hand thread and 1 left hand thread
- Machined trapezoidal thread conforming to BS 5346
- Thread tolerance: 7e
- Material: Half-hard steel







Uses

- Lathe drive screws
- Other machine tools

Machined thread

Accessories

- Steel and bronze nuts **BFM, VKM, SKM, LRM, KSM**

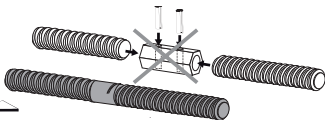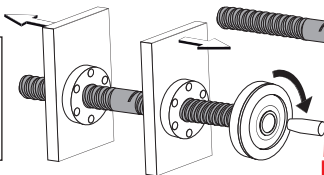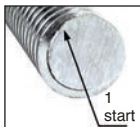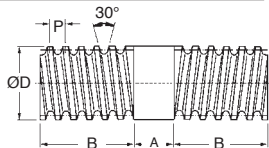

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD	Pitch P (mm)	A (mm)	B (mm)	Stock*	Price each 1 to 4
Length 1000mm						
LRH164-1	16	4	20	490	✓	77,64 €
LRH184-1	18	4	20	490	✓	90,15 €
LRH204-1	20	4	20	490	✓	104,30 €
LRH245-1	24	5	20	490	✓	118,91 €
LRH285-1	28	5	20	490	✓	132,85 €
LRH306-1	30	6	20	490	✓	144,31 €
LRH326-1	32	6	20	490	-	156,62 €
LRH366-1	36	6	20	490	✓	198,36 €
Length 2000mm						
LRH164-2	16	4	20	990	✓	156,72 €
LRH184-2	18	4	20	990	-	181,93 €
LRH204-2	20	4	20	990	✓	210,54 €
LRH245-2	24	5	20	990	✓	239,90 €
LRH285-2	28	5	20	990	✓	267,89 €
LRH306-2	30	6	20	990	✓	291,02 €
LRH326-2	32	6	20	990	-	315,79 €
LRH366-2	36	6	20	990	-	399,95 €

*Depending on availability - Dimensions in mm

Our other products



UGH32

H Type Guide units,
For Ø32 actuators



NKX

Combined bearing
without inner ring,
Needle and ball
bearings



BABPass

Hardened stainless
steel ball pin with
ring, With grip ring



CLA

Clamping lever
Hygienic Usit® -
female, Stainless steel



CHA1056-U4

Screwed hinge, 180°



PNA_R

PERIFLEX elastic
coupling,
Replacement tyre



SBS_L

Chain link, Stainless
steel



T5_11

T type timing pulley,
T5 aluminium



PRS80

Stainless steel
articulated foot Ø80,
Ø 80



HS

Hexagonal spacer,
Stainless steel 303



WS10

Drylin® W rail, Rail



FF50

Offset spur gear
reducer, from 111 to
425 Nm

Complementary products



BFM

Flanged bronze nut,
Bronze - 1 thread



LRM

Trapezoidal bronze
nut, Bronze - 1 thread