

LRH 1 right hand start, 1 left hand start

- Lead screw with 1 right hand thread and 1 left hand thread
- Machined trapezoidal thread conforming to BS 5346
- Thread tolerance: 7e
- Material: Half-hard steel







Uses

- Lathe drive screws
- Other machine tools

Machined thread

Accessories

- Steel and bronze nuts **BFM, VKM, SKM, LRM, KSM**

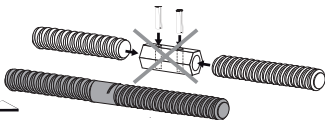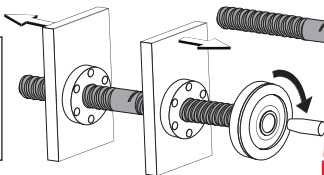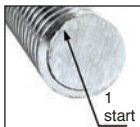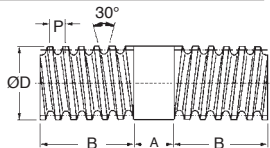

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD	Pitch P (mm)	A (mm)	B (mm)	Stock*	Price each 1 to 4
Length 1000mm						
LRH164-1	16	4	20	490	✓	77,64 €
LRH184-1	18	4	20	490	✓	90,15 €
LRH204-1	20	4	20	490	✓	104,30 €
LRH245-1	24	5	20	490	✓	118,91 €
LRH285-1	28	5	20	490	✓	132,85 €
LRH306-1	30	6	20	490	✓	144,31 €
LRH326-1	32	6	20	490	-	156,62 €
LRH366-1	36	6	20	490	✓	198,36 €
Length 2000mm						
LRH164-2	16	4	20	990	✓	156,72 €
LRH184-2	18	4	20	990	-	181,93 €
LRH204-2	20	4	20	990	✓	210,54 €
LRH245-2	24	5	20	990	✓	239,90 €
LRH285-2	28	5	20	990	✓	267,89 €
LRH306-2	30	6	20	990	✓	291,02 €
LRH326-2	32	6	20	990	-	315,79 €
LRH366-2	36	6	20	990	-	399,95 €

*Depending on availability - Dimensions in mm

Our other products



CFF_SS
Female rod ends DIN ISO12240-4, Stainless steel / bronze - Economy r...




DER71
Stainless steel AC asynchronous motor 0.25 à 0.37kW, 0.25 to 0.37kW



ATZY
Diabolo shaped elastomount, Steel



 MRASSeco
Low cost stainless steel quick link, Stainless steel



RPPM
RPP type belt per metre, RPP5 Steel cored polyurethane



BLHB40
Right angled gearbox, bored shafts, up to 10.3 Nm




SHA
Handwheel without handle, Polyamide



CQA30
Accessory for adjustment slide-system, 30



 MSP3815
Masterplate® glueable insert rectangular,



TC1rp
Automatic chain tensioner, With 180° guide



PRS30
Stainless steel articulated foot Ø30, Ø 30



AT10courroie
AT type timing belt, AT10 Steel cored polyurethane

Complementary products



BFM
Flanged bronze nut, Bronze - 1 thread



LRM
Trapezoidal bronze nut, Bronze - 1 thread