

LRH 1 right hand start, 1 left hand start

- Lead screw with 1 right hand thread and 1 left hand thread
- Machined trapezoidal thread conforming to BS 5346
- Thread tolerance: 7e
- Material: Half-hard steel







Uses

- Lathe drive screws
- Other machine tools

Machined thread

Accessories

- Steel and bronze nuts **BFM, VKM, SKM, LRM, KSM**

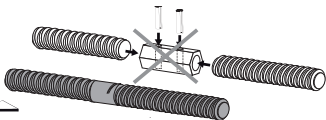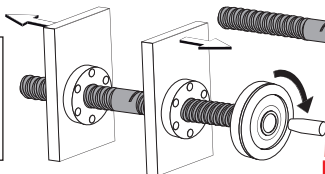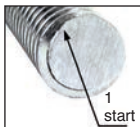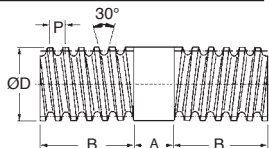

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD	Pitch P (mm)	A (mm)	B (mm)	Stock*	Price each 1 to 4
Length 1000mm						
LRH164-1	16	4	20	490	✓	77,64 €
LRH184-1	18	4	20	490	✓	90,15 €
LRH204-1	20	4	20	490	✓	104,30 €
LRH245-1	24	5	20	490	✓	118,91 €
LRH285-1	28	5	20	490	✓	132,85 €
LRH306-1	30	6	20	490	✓	144,31 €
LRH326-1	32	6	20	490	-	156,62 €
LRH366-1	36	6	20	490	✓	198,36 €
Length 2000mm						
LRH164-2	16	4	20	990	✓	156,72 €
LRH184-2	18	4	20	990	-	181,93 €
LRH204-2	20	4	20	990	✓	210,54 €
LRH245-2	24	5	20	990	✓	239,90 €
LRH285-2	28	5	20	990	✓	267,89 €
LRH306-2	30	6	20	990	✓	291,02 €
LRH326-2	32	6	20	990	-	315,79 €
LRH366-2	36	6	20	990	-	399,95 €

*Depending on availability - Dimensions in mm

Our other products



ACM_AZ
Mounting bracket for bonnet fastener, Hook



MLY
Bow shackle with eye bolt, Steel



PRF_P
Anchor foot for 45x45 profile, Anchor foot



AFM
Flanged polymer bush, Food grade polymer



NDS14C
Angular connector, Universal angular connector




BDP2R
Adjustable support arm, Increased grip



TSRTC
Stem support for caster, For swivel caster with central hole



 NKIB
Combined bearing with inner ring, Axial load in both directions



MO
Worm and wheel set, Machined plastic (delrin)



DHX
Dowel pin internal thread, Extractable DIN 7979D



BOXsap
Boxed set of spring pins ISO8752, Boxed set - Split ISO 8752



SBF
Open flange bearing unit for food industry, cover

Complementary products



BFM
Flanged bronze nut, Bronze - 1 thread



LRM
Trapezoidal bronze nut, Bronze - 1 thread