


 


 
- Lead screw with 1 right hand thread and 1 left hand thread
- Machined trapezoidal thread conforming to DIN 103
- Thread tolerance: 7e class 100
- Machined
- Material: Stainless steel 304

Uses

- Machine tools
- Lathe main screw

stainless steel

NEW!

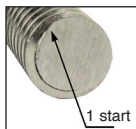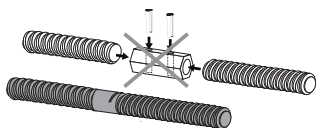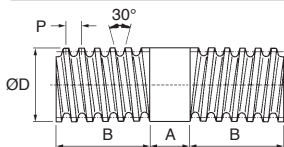


DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-5%	On request

Part number	ØD	Pitch P (mm)	A (mm)	B (mm)	Prix each
Length 1000mm					
LRH164-1/SS	16	4	20	490	
LRH184-1/SS	18	4	20	490	
LRH204-1/SS	20	4	20	490	
LRH245-1/SS	24	5	20	490	
LRH306-1/SS	30	6	20	490	
LRH326-1/SS	36	6	20	490	
Length 2000mm					
LRH164-2/SS	16	4	20	990	
LRH184-2/SS	18	4	20	990	
LRH204-2/SS	20	4	20	990	
LRH245-2/SS	24	5	20	990	
LRH306-2/SS	30	6	20	990	
LRH326-2/SS	36	6	20	990	

Dimensions in mm

 Our other products



CAB

Stainless steel cable,
Stainless steel



PRF_FIX_STD

Fastener for
aluminium profile,
Standard fastener



LFM2

Steel leadscrew,
Medium carbon steel -
2 threads



HG8-ECO

Eco range Spur gear,
Steel C45



CHAR7530

Spring hinge, welded



EZY

Cylindrical stop, Steel



 
RAGFLOWsupport

Floway2® Roller track
accessory, Roller
track support



DIV_SS

Stainless steel locking
bolt, With grip -
Stainless steel



MR_MMR

Metric section rack,
Steel



NT122

Spur gear coaxial
gearbox, from 32 to
85 Nm - Inline



BPHR

Ball transfer unit
housed spring loaded,
High



SPIT

Floor mounting
levelling plate, With
anchoring point

Complementary products