


 


 
- Lead screw with 1 right hand thread and 1 left hand thread
- Machined trapezoidal thread conforming to DIN 103
- Thread tolerance: 7e class 100
- Machined
- Material: Stainless steel 304

### Uses

- Machine tools
- Lathe main screw

stainless steel

NEW!

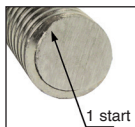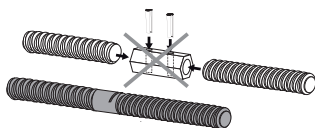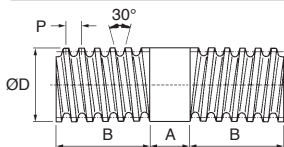

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-5%	On request

Part number	ØD	Pitch P (mm)	A (mm)	B (mm)	Prix each
<b>Length 1000mm</b>					
LRH164-1/SS	16	4	20	490	
LRH184-1/SS	18	4	20	490	
LRH204-1/SS	20	4	20	490	
LRH245-1/SS	24	5	20	490	
LRH306-1/SS	30	6	20	490	
LRH326-1/SS	36	6	20	490	
<b>Length 2000mm</b>					
LRH164-2/SS	16	4	20	990	
LRH184-2/SS	18	4	20	990	
LRH204-2/SS	20	4	20	990	
LRH245-2/SS	24	5	20	990	
LRH306-2/SS	30	6	20	990	
LRH326-2/SS	36	6	20	990	

Dimensions in mm

## Our other products



BOXdhx

Boxed set of threaded dowel pins DIN7979D, Boxed set - extractable D...



FRtool

Tool for thread repair inserts, Assembly tool



EP7

Electronic digital position indicator, 5 numbers



P45

Worm and wheel gear reducer, up to 40 Nm



PR125

Articulated foot Ø123, Ø 123



 
PITAss

Locking bolt, with T handle



BPHF

Ball transfer unit push fit, Heavy



P15

Worm and wheel gear reducer, up to 3,75 Nm



AFSE

Locking pin with interlocking safety latch, with



RFK58C

Hypoid gearbox - Stainless steel, up to 500 Nm



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - steel



RFV63

Stainless steel worm and wheel gearbox, up to 152 Nm

## Complementary products



LRM

Trapezoidal bronze nut, Bronze - 1 thread



 
BFM

Flanged bronze nut, Bronze - 1 thread



BAGtr

Lead screw clamping collar, Aluminium



VKM

Square steel nut, Steel - 1 thread