


# Trapezoidal bronze nut



## LRM LRMLH

### 1 start, right or left hand

- Right or left hand thread
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P

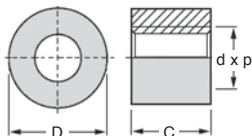

### Accessories

- LFM steel lead screw or LSM stainless steel screw

### DISCOUNTS <sup>A</sup>

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

### DISCOUNTS <sup>B</sup>

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Ød	Pitch P	D	C	Weight (kg)	Stock*	Price each	
							1 to 9	20 to 39**
<b>Right-hand thread</b>								
LRM102	10	2	22	20	0,053	✓	A 14,47 €	A 8,69 €
LRM123	12	3	26	24	0,083	✓	A 14,04 €	A 8,42 €
LRM143	14	3	30	28	0,135	✓	A 18,06 €	A 10,83 €
LRM164	16	4	36	32	0,232	✓	A 25,15 €	A 15,09 €
LRM184	18	4	40	36	0,320	✓	A 31,85 €	A 19,11 €
LRM204	20	4	45	40	0,455	✓	A 40,99 €	A 24,59 €
LRM225	22	5	45	44	0,480	✓	A 44,26 €	A 26,56 €
LRM245	24	5	50	48	0,656	✓	A 55,88 €	A 33,53 €
LRM285	28	5	60	56	1,102	✓	A 89,64 €	A 53,78 €
LRM306	30	6	60	60	1,140	✓	A 91,03 €	A 54,62 €
LRM326	32	6	60	64	1,177	✓	A 96,50 €	A 57,90 €
LRM366	36	6	75	72	2,189	✓	B 109,86 €	B On request
LRM407	40	7	80	80	2,725	✓	B 142,29 €	B On request
LRM447	44	7	80	88	2,815	-	B 155,05 €	B On request
LRM508	50	8	90	100	4,014	-	B 208,02 €	B On request
LRM609	60	9	100	120	5,150	-	B 276,00 €	B On request
<b>Left-hand thread</b>								
LRM102/LH	10	2	22	20	0,053	✓	A 17,49 €	A 10,50 €
LRM123/LH	12	3	26	24	0,083	✓	A 15,79 €	A 9,48 €
LRM143/LH	14	3	30	28	0,135	-	A On request	A On request
LRM164/LH	16	4	36	32	0,232	✓	A 27,65 €	A 16,59 €
LRM184/LH	18	4	40	36	0,320	✓	A 43,63 €	A 26,18 €
LRM204/LH	20	4	45	40	0,455	✓	A 44,80 €	A 26,88 €
LRM225/LH	22	5	45	44	0,480	✓	A 61,29 €	A 36,77 €
LRM245/LH	24	5	50	48	0,656	✓	A 58,97 €	A 35,38 €
LRM285/LH	28	5	60	56	1,102	✓	A 108,45 €	A 65,07 €
LRM306/LH	30	6	60	60	1,140	✓	A 104,30 €	A 62,58 €
LRM326/LH	32	6	60	64	1,177	✓	A 115,48 €	A 69,28 €
LRM366/LH	36	6	75	72	2,189	-	B 117,47 €	B On request
LRM407/LH	40	7	80	80	2,725	-	B 146,77 €	B On request
LRM447/LH	44	7	80	88	2,815	-	B 164,57 €	B On request
LRM508/LH	50	8	90	100	4,014	-	B 246,62 €	B On request
LRM609/LH	60	9	100	120	5,150	-	B 319,78 €	B On request

\*Depending on availability - Dimensions in mm

\*\* refer to discounts

## Our other products



BAB

Hardened Stainless steel ball pin, Stainless steel hardened



SVR15

Screwjack with travelling nut, with moving nut



PSG085

Spur gear - precision range, Stainless steel 303



STRIP

Sealing brush strip, 3m length



GP

Spring loaded toggle latch, With padlock-holder



DILC

Indexing plunger with cam, with cam



PTKss

Foot for the food industry, Stainless steel - 3-A standard



TBD

Manual leadscrew table with opposing threads, 40kg



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



BLHB60

Right angled gearbox, bored shafts, up to 70 Nm



PRES7HR

Manual workbench press, Force up to 700kg



AT10-25ECO

AT type timing pulley, Economy range - AT10 aluminium

## Complementary products



 
LFM

Steel leadscrew, Medium carbon steel - 1 thread



LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread



LRH

Bi-directional leadscrew, Bi-directional - 1 thread