


- Thread conforms to NFE 03.616
- Machined nut
- Material: Bronze UE
- Thread tolerance: 7H


Accessories

- LFM 2 start steel leadscrew

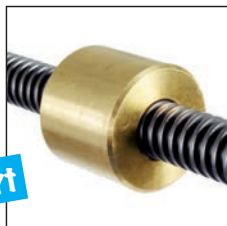

2 Start

40% DISCOUNTS
for 20-39 off

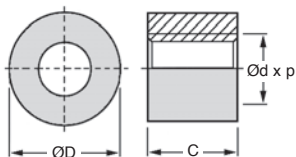

DISCOUNTS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

Part number	Ød	Pitch P	D	C	Weight (kg)	Price each	
						1 to 9	40 to 59**
LRM126	12	6	26	24	0,083	20,22 €	12,13 €
LRM168	16	8	36	32	0,232	32,11 €	19,26 €
LRM188	18	8	40	36	0,320	43,09 €	25,85 €
LRM208	20	8	45	40	0,455	48,13 €	28,88 €
LRM2210	22	10	45	44	0,480	61,29 €	36,77 €
LRM2410	24	10	50	48	0,656	67,93 €	40,76 €
LRM2810	28	10	60	56	1,102	108,45 €	65,07 €
LRM3012	30	12	60	60	1,140	104,30 €	62,58 €
LRM3212	32	12	60	64	1,177	115,48 €	69,28 €
LRM3612	36	12	75	72	2,189	182,57 €	109,54 €
LRM4014	40	14	80	80	2,725	227,60 €	136,56 €

Dimensions in mm

Our other products



PRF_ROUL

Castor for aluminium profile, No brake



EBC

Cap nut Hygienic Design®, Compact



MDB_MTB

Moulded plastic bevel gear (nylon), 3:1



CFS

Miniature cam follower, Miniature



BCH_SS

Mushroom headed button, M3 to M8



PAP

Handle for aluminium profile, Ergonomic handle



RT25ss

Self-centering flanged locking assembly, Medium/high torque



 
BABT

Hardened Stainless steel ball pin, Hardened stainless steel



CHTRB

Single and dual output gearboxes, Up to 4,7 Nm



PRL

Wear strip for slat top chain, L profile to be clipped



RT61

Self-centering locking Assembly, Medium/low torque



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane

Complementary products



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



LFM2

Steel leadscrew, Medium carbon steel - 2 threads