


- Thread conforms to NFE 03.616
- Machined nut
- Material: Bronze UE
- Thread tolerance: 7H


### Accessories

- LFM 2 start steel leadscrew

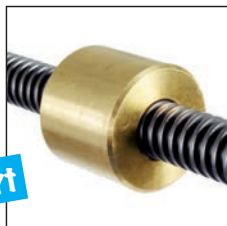

2 Start

40% DISCOUNTS  
for 20-39 off

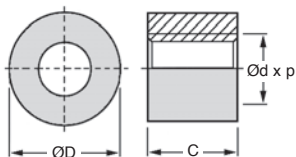

### DISCOUNTS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

Part number	Ød	Pitch P	D	C	Weight (kg)	Price each	
						1 to 9	40 to 59**
LRM126	12	6	26	24	0,083	20,22 €	12,13 €
LRM168	16	8	36	32	0,232	32,11 €	19,26 €
LRM188	18	8	40	36	0,320	43,09 €	25,85 €
LRM208	20	8	45	40	0,455	48,13 €	28,88 €
LRM2210	22	10	45	44	0,480	61,29 €	36,77 €
LRM2410	24	10	50	48	0,656	67,93 €	40,76 €
LRM2810	28	10	60	56	1,102	108,45 €	65,07 €
LRM3012	30	12	60	60	1,140	104,30 €	62,58 €
LRM3212	32	12	60	64	1,177	115,48 €	69,28 €
LRM3612	36	12	75	72	2,189	182,57 €	109,54 €
LRM4014	40	14	80	80	2,725	227,60 €	136,56 €

Dimensions in mm

## Our other products



CAP815

Slim slat top chain  
stainless steel,  
Narrow range 815



F7-P-AM

Multifunction display,  
Magnetic ring



M1

Worm and wheel set,  
Non hardened steel



ADL\_F

Female eye bolt  
conforms to DIN582,  
Steel



PCS\_PA6

Plastic sprocket,  
9.525mm (DIN 06B-1)



PSPD40

Flexible tube handle,  
Black PVC




NRV

Orthogonal support  
clamp, Orthogonal  
support clamp



WW20

 Drylin® W slide, slide  
assembly



M2

Worm and wheel set,  
Machined plastic  
(delrin)



GP

Spring loaded toggle  
latch, Standard



Q4

Double row radial  
contact ball bearing,  
Radial contact - Steel



BEK

Bearing housing for  
miniature ballscrew,  
Bearing housing

## Complementary products



LFM2

Steel leadscrew,  
Medium carbon steel -  
2 threads



LFM2

Steel leadscrew,  
Medium carbon steel -  
2 threads