

- Thread conforms to NFE 03.616
- Machined nut
- Material: Bronze UE
- Thread tolerance: 7H


Accessories

- LFM 2 start steel leadscrew



2 Start

**40% DISCOUNTS
for 20-39 off**

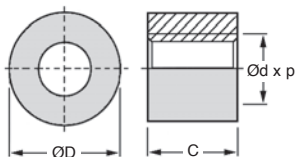

DISCOUNTS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

Part number	Ød	Pitch P	D	C	Weight (kg)	Price each	
						1 to 9	40 to 59**
LRM126	12	6	26	24	0,083	20,22 €	12,13 €
LRM168	16	8	36	32	0,232	32,11 €	19,26 €
LRM188	18	8	40	36	0,320	43,09 €	25,85 €
LRM208	20	8	45	40	0,455	48,13 €	28,88 €
LRM2210	22	10	45	44	0,480	61,29 €	36,77 €
LRM2410	24	10	50	48	0,656	67,93 €	40,76 €
LRM2810	28	10	60	56	1,102	108,45 €	65,07 €
LRM3012	30	12	60	60	1,140	104,30 €	62,58 €
LRM3212	32	12	60	64	1,177	115,48 €	69,28 €
LRM3612	36	12	75	72	2,189	182,57 €	109,54 €
LRM4014	40	14	80	80	2,725	227,60 €	136,56 €

Dimensions in mm

Our other products



CHB

Reaction arm, CHB gear reducers reaction arm



S2B

Short linear bearing housing, Closed - Slim



 
MFB_MHB

Moulded plastic bevel gear (nylon), 4:1



VTSM

Ball head screws Hygienic Design®, Stainless steel



AC

Strike for toggle latch, 20mm



PRF3232

Standard aluminium profile, 32 x 32 mm



CAP882

Flexible slat top chain acetal, Large range 882



Q4

Double row radial contact ball bearing, Radial contact - Steel



P20

Worm and wheel gear reducer, up to 5 Nm



MAX22

Motor-gearbox 12V and 24V DC, from



M0

Worm and wheel set, Machined plastic



PCS50

Chain sprocket - steel, 12.7mm (DIN08B-1)

Complementary products



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



LFM2

Steel leadscrew, Medium carbon steel - 2 threads