


- Thread conforms to NFE 03.616
- Machined nut
- Material: Bronze UE
- Thread tolerance: 7H


Accessories

- LFM 2 start steel leadscrew

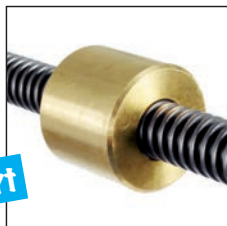

2 Start

40% DISCOUNTS
for 20-39 off

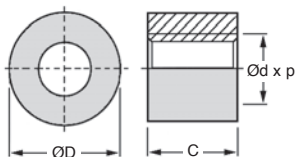


DISCOUNTS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

Part number	Ød	Pitch P	D	C	Weight (kg)	Price each	
						1 to 9	40 to 59**
LRM126	12	6	26	24	0,083	20,22 €	12,13 €
LRM168	16	8	36	32	0,232	32,11 €	19,26 €
LRM188	18	8	40	36	0,320	43,09 €	25,85 €
LRM208	20	8	45	40	0,455	48,13 €	28,88 €
LRM2210	22	10	45	44	0,480	61,29 €	36,77 €
LRM2410	24	10	50	48	0,656	67,93 €	40,76 €
LRM2810	28	10	60	56	1,102	108,45 €	65,07 €
LRM3012	30	12	60	60	1,140	104,30 €	62,58 €
LRM3212	32	12	60	64	1,177	115,48 €	69,28 €
LRM3612	36	12	75	72	2,189	182,57 €	109,54 €
LRM4014	40	14	80	80	2,725	227,60 €	136,56 €

Dimensions in mm

 Our other products



P40

Worm and wheel gear reducer, up to 18 Nm



ETP

Modular handle for aluminium profile, Modular handle



PTR

Idler chain sprocket, For standard applications



DB

Steel bevel gear, 2:1




PRSS0

Stainless steel articulated foot Ø50, Ø 50



MHWC

 Double-disc flexible coupling, Double disk




T5courroie

T type timing belt, T5 Steel cored polyurethane



PR85

 Articulated foot Ø83, Ø 83



PRF LIS

Door seal for aluminium profile,




AT10-32ECO

AT type timing pulley, Economy range -



TBD

 Manual leadscrew table with opposing



KSM

Cylindrical steel nut, Steel - 1 thread

Complementary products



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



LFM2

Steel leadscrew, Medium carbon steel - 2 threads