

Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials :
Galvanised steel

Accessory

- Catch plate LRRgpv (tome 5 p.213)

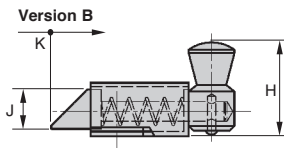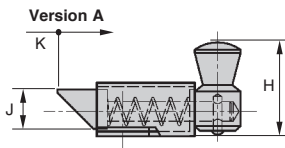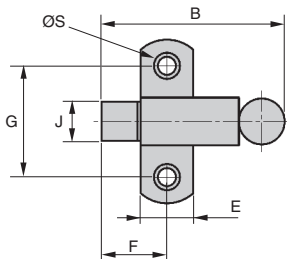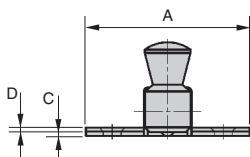

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
Version A															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
Version B															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

*Depending on availability - Dimensions in mm



- Catch for sprung latch LRR

- Materials :

Galvanised steel

Accessory

- Spring loaded latch LRR (tome 5 p.212)

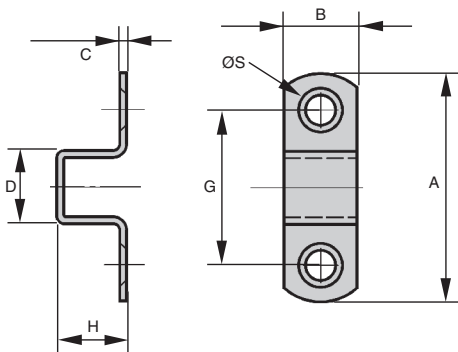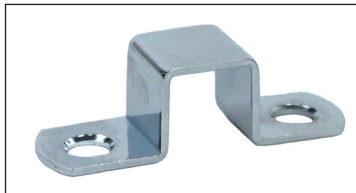

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock ¹	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €

*Depending on availability - Dimensions in mm

Our other products



ACLEPP

Right angled bracket for aluminium profile, 8 holes



BAN

Angular clamp, Universal




VPR

Wing screw Hygienic Usit®, Stainless steel



SCA_SS

Stainless steel flat cable clamp, Stainless steel

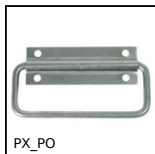

PX_PO

Carrying handle, standard



PR820

Idler sprocket for slat top chain, Rangs 820 and 815



MACss

Stainless steel carabiner, Stainless steel



ZG4

Plastic spur gear, Machined plastic (delrin)



RUR

Wheel, Polyurethane - Aluminium rim (Free)



TSRTC

Stem support for caster, For swivel



KK

Rounded end feather key, Steel



MRAeco

Low cost quick link, Steel

Complementary products



LRRss

Latch, Spring loaded latch - stainless steel



LRR

Spring loaded latch, Spring loaded latch



LRR-53

Spring loaded latch, Spring return latch - stainless steel