

Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials :
Galvanised steel

Accessory

- Catch plate LRRgpv (tome 5 p.213)

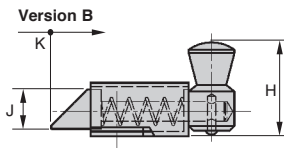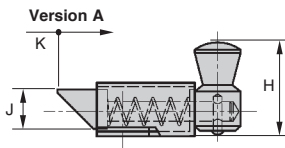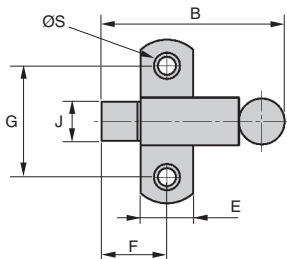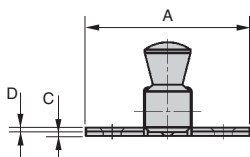

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
Version A															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
Version B															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

*Depending on availability - Dimensions in mm



- Catch for sprung latch LRR

- Materials :

Galvanised steel

Accessory

- Spring loaded latch LRR (tome 5 p.212)

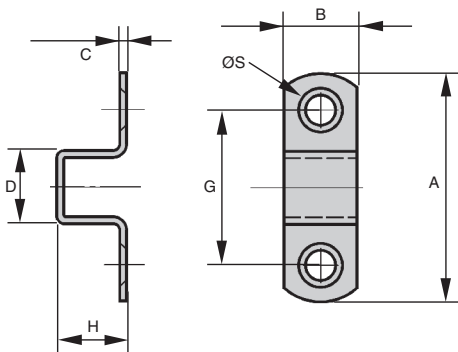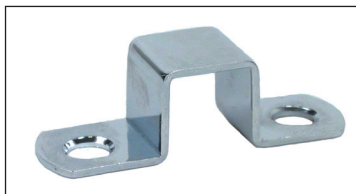

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock ¹	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €

*Depending on availability - Dimensions in mm

Our other products



CHMR30

Worm and wheel gear reducer, up to 28 Nm



HG5

Steel spur gear, Steel 20NCD2



M2

Worm and wheel set, Hardened steel



PRF-SCREEN-4

Screen support, Support with 4 axes of rotation



WFRM

Flanged polymer nut, Polymer (Iglidur®) - 1 thread



MFBSC

Stainless steel flexible bellows coupling, Stainless steel - with cl...



UGH20

H Type Guide units, For Ø20 actuators



SSDB

Stainless steel bevel gear, 2:1



CLAT

Clamping lever Hygienic Usit® - male, Stainless steel



SLV

Vertical toggle clamp, Vertical Lever Clamp - steel



PW_PWG3

Wheel - precision range, Bronze



STC

Shock Absorber - stop collar, Universal flange

Complementary products



LRRss

Latch, Spring loaded latch - stainless steel



LRR

Spring loaded latch, Spring loaded latch



LRR-53

Spring loaded latch, Spring return latch - stainless steel