

# Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials :  
Galvanised steel

## Accessory

- Catch plate LRRGPV (tome 5 p.197)

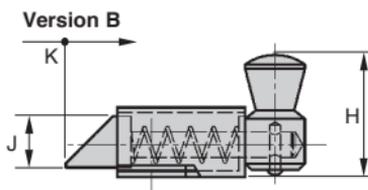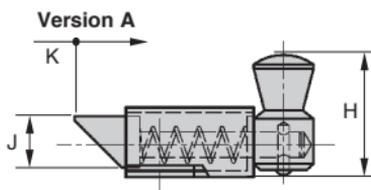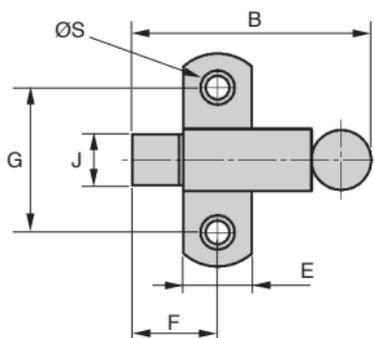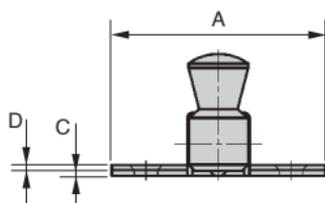

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
<b>Version A</b>															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	22,27 €
<b>Version B</b>															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	22,27 €

\*Depending on availability - Dimensions in mm


- Catch for sprung latch LRR

- Materials :

Galvanised steel

## Accessory

- Spring loaded latch LRR (tome 5 p.196)

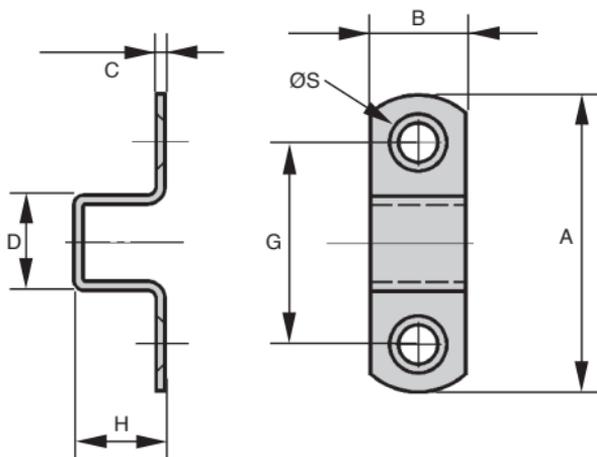

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock <sup>*</sup>	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,26 €

\*Depending on availability - Dimensions in mm

- Slam latches for direct closing in hostile environments

- Latch tongue at top

- Resistant to water and cleaning products

- Materials:

Body and support: 304L stainless steel

Latch and handle: 303 stainless steel

Spring: 301 stainless steel

### Advantages

- Openings on the top and mounting face allow easy cleaning (no retention of water or dirt)

- No sharp angles (avoids risk of injury)

- Top mounted handle allows easy opening

 





### Applications

- Equipment for the food industry


- Animal breeding (hutches, hen-houses)

- Lids for metal enclosures used in humid environments

- Stainless steel strike plate not supplied

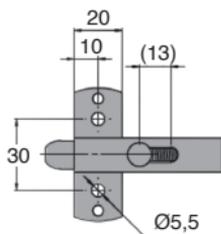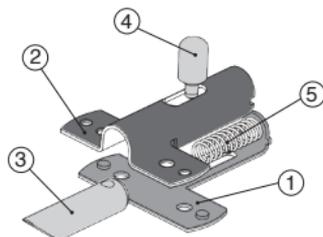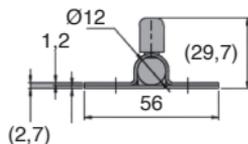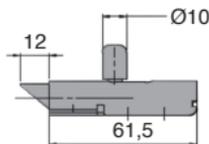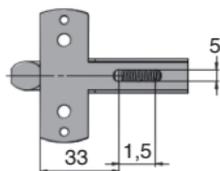

A version

 

B version

### DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request



Part number	Latch stroke (mm)	Type	Stock*	Price each 1 to 9
LRR-56-A/SS	12	A version	✓	30,53 €
LRR-56-B/SS	13	B version	✓	41,68 €

Dimensions in mm. \*Depending on availability


- **Spring loaded single bolt**
- Rolled knot hinge
- Material:  
White galvanized steel  
Stainless steel 304

### Advantages

- Simple locking
- Retractable pivot

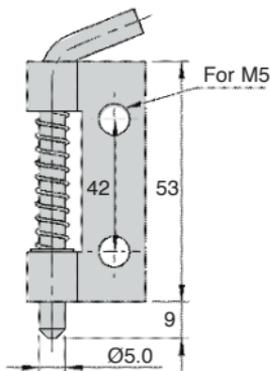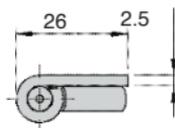

Right handed

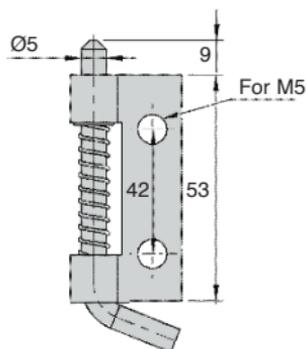

Left handed

### DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-10%	On request	

Part number	Version	Stock*	Price each 1 to 49
<b>Steel version</b>			
LRR-53-26/D	Right	✓	3,25 €
LRR-53-26/G	Left	-	3,25 €
<b>Stainless steel version</b>			
LRR-53-26/G/SS	Left	✓	6,51 €
LRR-53-26/D/SS	Right	✓	6,51 €

\*Depending on availability - Dimensions in mm

# Small dimension latch with locking system Alu

## LRR22


## In aluminium

- **Springloaded bolt can be held in unlocked position**

- **Materials:**


Body: aluminium 6060T5 clear anodised  
 Shaft and handle: raw aluminium  
 Cap: Black PE  
 Spring: Stainless steel  
 Strike: aluminium 5754 clear anodised

*Held unlocked*

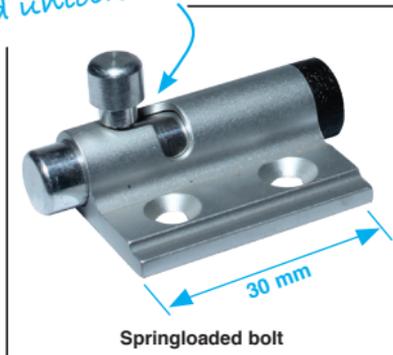


### Note


There is no strike for this size

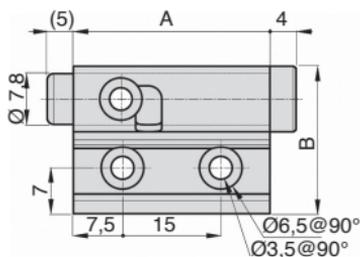

**Type 2**  
LRR-22-2/ALU

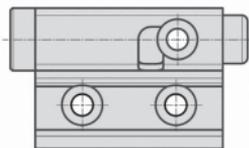

**Type 1**  
LRR-22-1/ALU

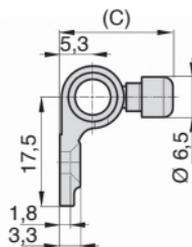

### DISCOUNT

<b>Qty</b>	1+	10+	20+	50+
<b>Disc. List</b>	-3%	-5%	On request	

Part number	A	B	C	Type	Weight (g)	Price each 1 to 9
<b>Springloaded bolt</b>						
LRR-22-2/ALU	30	22,5	18,2	2	9	17,19 €
LRR-22-1/ALU	30	22,5	18,2	1	9	17,19 €

Dimensions in mm

- **Springloaded bolt can be held in unlocked position**

- It is recommended to combine 1 latch with 1 strike

- Materials:

Body: aluminium 6060T5 clear anodised

Shaft and handle: raw aluminium

Cap: Black PE

Spring: Stainless steel


Strike: aluminium 5754 clear anodised




Springloaded bolt





Strike

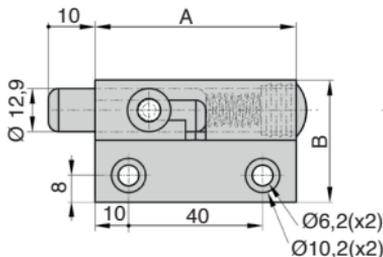

Type 2  
LRR-37-2/ALU

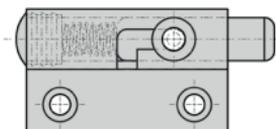

Type 1  
LRR-37-1/ALU

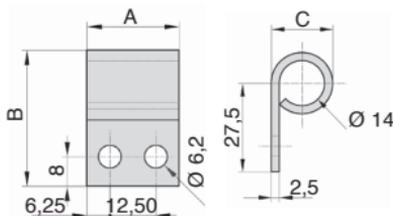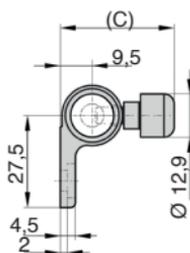

LRR-37-GPV/ALU


### DISCOUNT

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	C	Type	Weight (g)	Price each 1 to 9
<b>Springloaded bolt</b>						
LRR-37-2/ALU	60	36,5	34	2	58	28,02 €
LRR-37-1/ALU	60	36,5	34	1	58	28,02 €
<b>Strike</b>						
LRR-37-GPV/ALU	25	37	19	-	11	4,96 €

Dimensions in mm

- Quick closing catch
- Push to close
- Material:  
Chromed die cast zinc

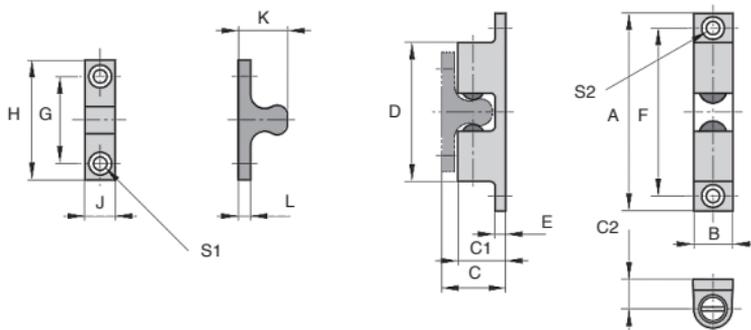

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	C1	C2	D	E	F	G
LQT-2B-42-8	42,5	8,0	14,0	10,0	6,5	26,7	2,5	35	16
LQT-2B-50-10	50,0	10,0	16,0	12,5	7,4	29,8	3,0	40	20
LQT-2B-70-13	70,0	13,5	21,2	17,0	11,0	49,0	4,0	60	30

Part number	H	J	K	L	S1	S2	Force (N)	Weight (g)	Stock*	Price each 1 to 5
LQT-2B-42-8	25	7,5	11,3	2,5	3,2	3,2	30	16	✓	13,80 €
LQT-2B-50-10	30	9,0	12,3	2,5	4,2	4,2	33	26	✓	16,24 €
LQT-2B-70-13	42	10,5	17,2	3	4,2	4,2	35	70	✓	28,00 €

\*Depending on availability - Dimensions in mm