

Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials :
Galvanised steel

Accessory

- Catch plate LRRgpv (tome 5 p.213)

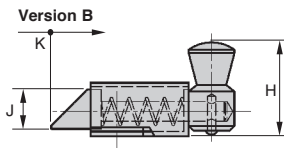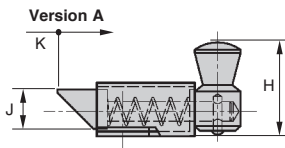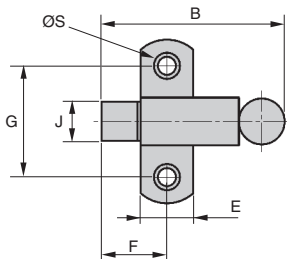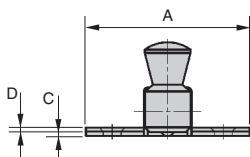

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
Version A															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
Version B															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

*Depending on availability - Dimensions in mm



- Catch for sprung latch LRR

- Materials :

Galvanised steel

Accessory

- Spring loaded latch LRR (tome 5 p.212)

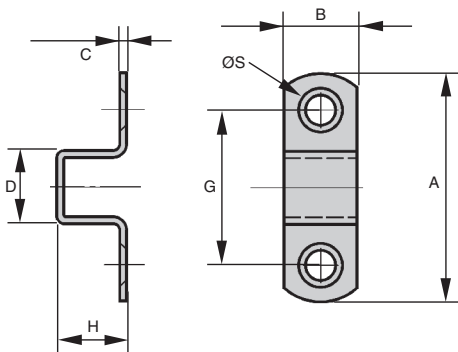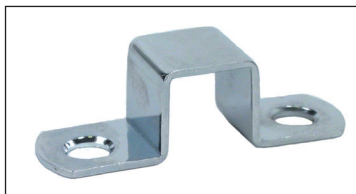

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock ¹	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €

*Depending on availability - Dimensions in mm

Our other products



RCX-6
Spherical tilt washer -
DIN6319, concave



RDERSS
Stainless steel manual
rigging screw,
Stainless steel -
manual



BCFH
Mushroom headed
button Hygienic
Usit®, With male
thread and high head



ZG4
Plastic spur gear,
Machined plastic
(delrin)




HLC24
Right angle spiro
bevel gearbox, Up to
78Nm



BOX-TOR-ORFS
Box set of Nitrile O-
rings NBR90Sh A, 7.65
x 1.78mm to 37.82 x
1.78



 BABV
Ball lock pins lockable
, Stainless steel



TBV
Manual lifting tables,
20kg



ASM
Cylindrical polymer
bush, Food grade



BOX-TOR-C
Box set of Nitrile O-
rings in nitrile, 3.00 x



BEK
Bearing housing for
miniature ballscrew,



Q6
Deep groove ball
bearing, Steel

Complementary products



LRRss
Latch, Spring loaded
latch - stainless steel



LRR
Spring loaded latch,
Spring loaded latch



LRR-53
Spring loaded latch,
Spring return latch -
stainless steel