

# Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials :  
Galvanised steel

## Accessory

- Catch plate LRRgpv (tome 5 p.213)

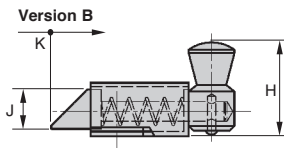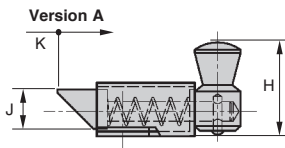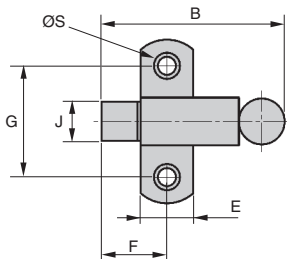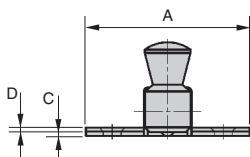

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
<b>Version A</b>															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
<b>Version B</b>															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

\*Depending on availability - Dimensions in mm



- Catch for sprung latch LRR

- Materials :

Galvanised steel

## Accessory

- Spring loaded latch LRR (tome 5 p.212)

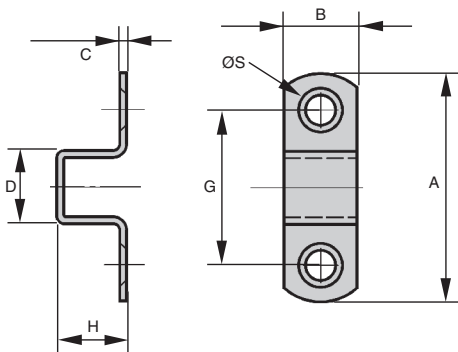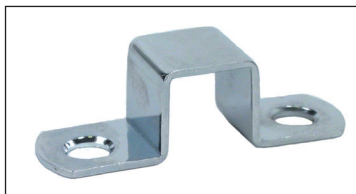

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock <sup>1</sup>	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €

\*Depending on availability - Dimensions in mm

## Our other products



RURt

Swivel castor with central hole, Polyurethane - Aluminium rim (Free



BTE

Universal tension arm, For normal applications



KK

Rounded end feather key, Steel



DOMI30

Accessories, Fixing kit



PCS25ECO

Chain sprocket - steel, 6.35mm



SEH

Horizontal stirrup toggle clamp, Horizontal Latch clamp - stainless ...



EKONSL

Silicone conical elastomer buffer, Female mounting



PF55

Worm and wheel gear reducer, up to 57 Nm




BLHT50

Right angled gearbox, from 11.50 to 30 Nm



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2

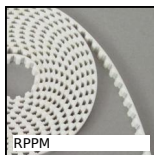

RPPM

RPP type belt per metre, RPP14 Steel cored polyurethane



MSP38

Masterplate® glueable insert Ø38, Cylindrical Ø38 with threaded s...

## Complementary products



LRR

Spring loaded latch, Spring loaded latch