

Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials : Galvanised steel

Accessory

- Catch plate LRRgpv (tome 5 p.213)

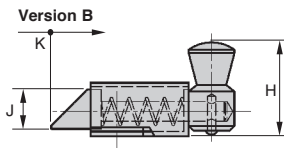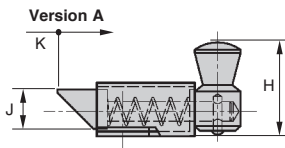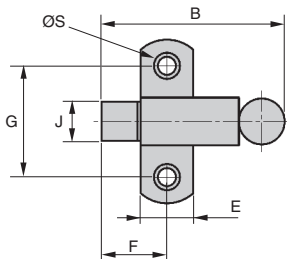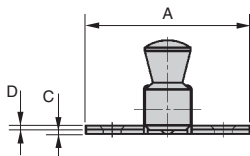

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
Version A															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
Version B															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

*Depending on availability - Dimensions in mm



- Catch for sprung latch LRR

- Materials :

Galvanised steel

Accessory

- Spring loaded latch LRR (tome 5 p.212)

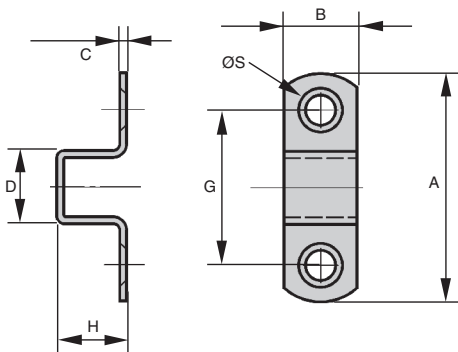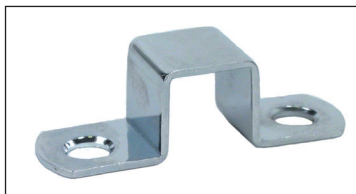

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock ¹	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €


*Depending on availability - Dimensions in mm

Our other products



SVG

Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm

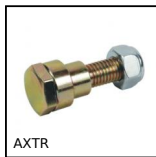

AXTR

Axle for tensioner pulley, Shaft



HAR9

Captive C washer, DIN 6371



CHAFR-MINI

Miniature friction hinge, Friction



gt64r

Rotating bent lever with spring, Increased fitting tolerances



LVT

Miniature motorised actuator 4A, 4 amperes



PRF_GAL

Roller for aluminium profile, Fixing kit for roller concentric



LF

Precision locknut, Precision locknut



RAGb

Cylindrical brush track, For gentle



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



HRV

V- rail guidance Simple Select®



WJUM10

Drylin® W bearing block, Slide

Complementary products



LRR

Catch-plate for latch, Catch-plate



LRRss

Latch, Spring loaded latch - stainless steel



LRR-53

Spring loaded latch, Spring return latch - steel



LRR22

Small dimension latch with locking system, Aluminium