

Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials :
Galvanised steel

Accessory

- Catch plate LRRgpv (tome 5 p.213)

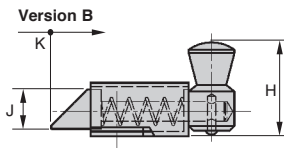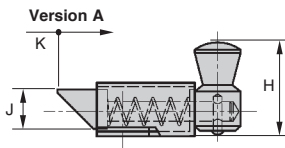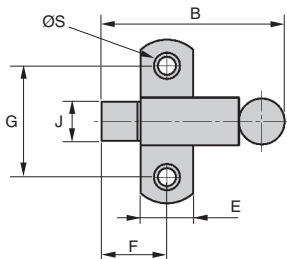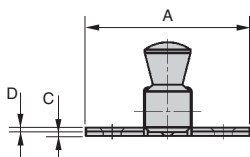

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
Version A															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
Version B															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

*Depending on availability - Dimensions in mm



- Catch for sprung latch LRR

- Materials :

Galvanised steel

Accessory

- Spring loaded latch LRR (tome 5 p.212)

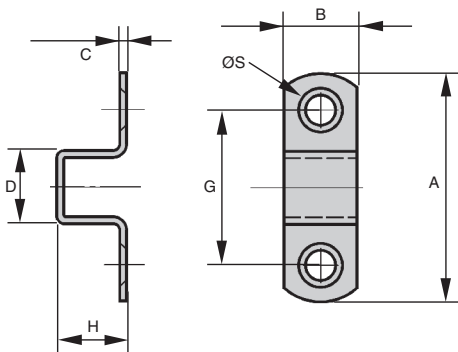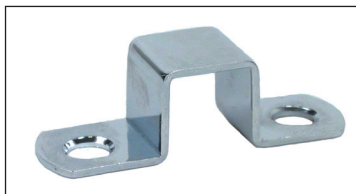

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock ¹	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €

*Depending on availability - Dimensions in mm

Our other products




EHD12

Internal epicyclic servo reducers, from 60 to 140 Nm



KITdog

24V DC motorisation kit, Worm and wheel

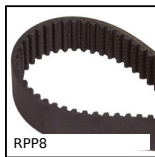

RPP8

RPP heavy duty timing belt, RPP8



M1

Worm and wheel set, Non hardened steel



ACLERP

Roller block for aluminium profile, Without guide rail



PRF_BM

Base support plate for aluminium profile, Central base fixation



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



WTM

Tightening washer - DIN6340, Steel



INO

Internal gear, Steel 20NCD2



T10_21N1F

T type timing pulley, Economy range - T10



PRF_SDD_1820

Support for Ø18 or Ø20mm Prox



MRA

Quick link, Steel

Complementary products



LRR

Spring loaded latch, Spring loaded latch