





Spring loaded latch

Stock Bra

LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials :
Galvanised steel

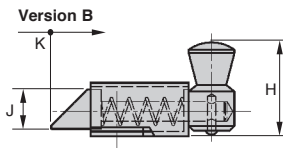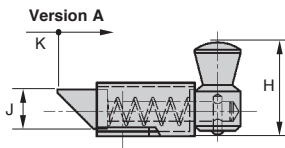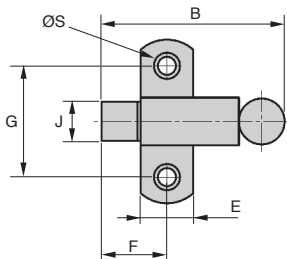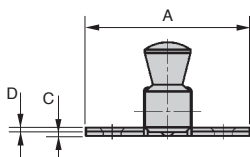

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
Version A															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
Version B															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

*Depending on availability - Dimensions in mm



HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

- Catch for sprung latch LRR
- Materials :
Galvanised steel

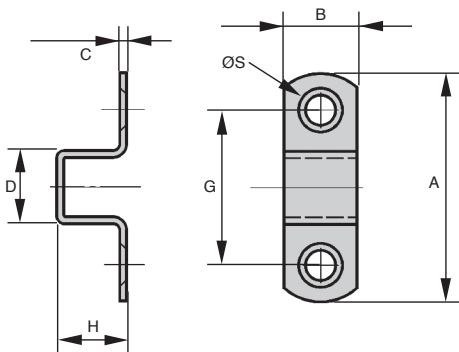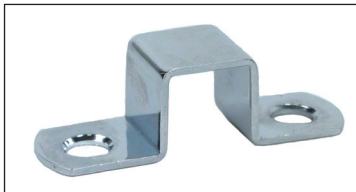

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock ¹	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €

*Depending on availability - Dimensions in mm

Our other products



PSG125DL

Spur gear - precision range, Peek



PF60

Worm and wheel gearbox, up to 118 Nm



PHG3

Parallel axis helical gear - Precision range, 20NCD2 case hardened steel



FB_ECO

Bevel gear - Steel C43, 4:1



BOX-TOR-MAX

Box set of Nitrile O-rings, 2.90 x 1.78mm to 82.14 x 3.53



HTD5M_25

HTD-type pulley for RPP-type belt, HTD5 Aluminium



CFS

Cam follower, Miniature



G3

Spur gear, Steel 20NCD2



TBD

Manual table with opposite threads, 25mm guide rods



AT5P_AT10P

Connecting plate, AT10



T5M_T10M

Timing belt per metre, T5 Steel cored polyurethane



VRC1

Retaining catch, Single sided

Complementary products



LRR

Latch, Catch-plate



LRRss

Latch, Spring loaded latch - stainless steel



LRR-53

Latch, Spring return latch - steel



LRR-53

Latch, Spring return latch - stainless steel