



# Small dimension latch with locking system

## In aluminium

## LRR22

- Springloaded bolt can be held in unlocked position

- Materials:

Body: aluminium 6060T5 clear anodised

Shaft and handle: raw aluminium

Cap: Black PE



Spring: Stainless steel

Strike: aluminium 5754 clear anodised


### Note

There is no strike for this size


Held unlocked

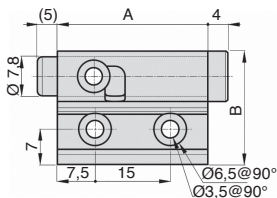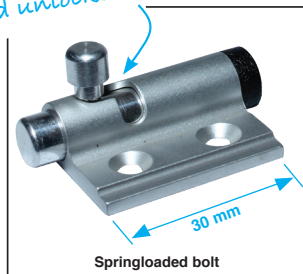

Type 2  
LRR-22-2/ALU

 

Type 1  
LRR-22-1/ALU

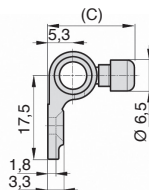


### DISCOUNT

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	C	Type	Weight (g)	Stock*	Price each 1 à 9
<b>Springloaded bolt</b>							
LRR-22-2/ALU	30	22,5	18,2	2	9	-	16,85 €
LRR-22-1/ALU	30	22,5	18,2	1	9	-	16,85 €

\*Depending on availability - Dimensions in mm

## Our other products

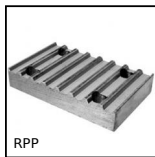

RPP

Connecting plate for RPP type timing belts, RPP8



BABTV

Ball lock pins lockable, Stainless steel



CHA

Heavy duty plastic hinge, opens 180°, Heavy duty - Opens 180°




BS3

Panamech, Multi-Beam stainless steel, Stainless steel - with set screw



BOX-TOR-G

 Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



TBL

Mini leadscrew table with metric thread, Base plate



GSI\_A

Gas control screw for gas spring, Gas control screw



S\_2RS

Deep groove ball bearing, Stainless steel



PW\_PWG2

Worm - precision range, Steel



OPFL\_OPPL

Numerical counter accessories, Locking clamp



BPHR

Ball transfer unit housed spring loaded, High



BPPL

Mini plain bearing ball transfer unit, For countersinking

## Complementary products



LRRRA

Latch with locking system, Aluminium



LRR

Spring loaded latch, Spring loaded latch



LRR

Catch-plate for latch, Catch-plate



LRRss

Latch, Spring loaded latch - stainless steel