



Small dimension latch with locking system

In aluminium

LRR22

- Springloaded bolt can be held in unlocked position

- Materials:

Body: aluminium 6060T5 clear anodised

Shaft and handle: raw aluminium

Cap: Black PE



Spring: Stainless steel

Strike: aluminium 5754 clear anodised


Note

There is no strike for this size


Held unlocked

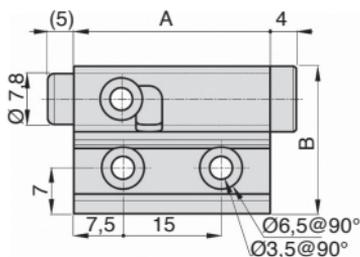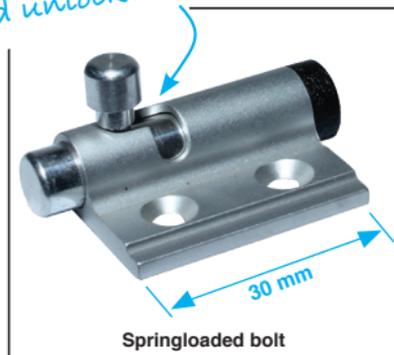

Type 2
LRR-22-2/ALU

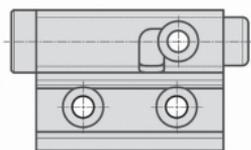

Type 1
LRR-22-1/ALU

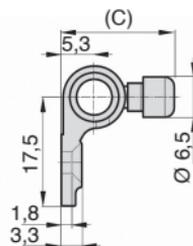

DISCOUNT

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	C	Type	Weight (g)	Stock*	Price each 1 à 9
Springloaded bolt							
LRR-22-2/ALU	30	22,5	18,2	2	9	-	16,85 €
LRR-22-1/ALU	30	22,5	18,2	1	9	-	16,85 €

*Depending on availability - Dimensions in mm

Our other products



BPH

Ball transfer unit plain fit, High



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel



CHT

Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW




CHAR6035

Spring hinge, screwed/welded



PCP

Cell carrier assembly, Ready assembled

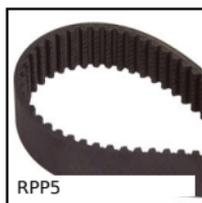

RPP5

RPP heavy duty timing belt, RPP5



MRA_SS

Stainless steel Quick link, Stainless steel



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



ZG0

Plastic spur gear, Machined plastic (delrin)



PSG08S

Spur gear - precision range, Stainless steel 303



DCG

Suction cup, 2.5 bellows, natural rubber



KB_WW

Closed linear precision bearing, Economy range

Complementary products