

- **Springloaded bolt can be held in unlocked position**

- It is recommended to combine 1 latch with 1 strike

- Materials:


Body: aluminium 6060T5 clear anodised

Shaft and handle: raw aluminium

Cap: Black PE

Spring: Stainless steel


Strike: aluminium 5754 clear anodised

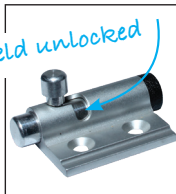


Springloaded bolt





Strike

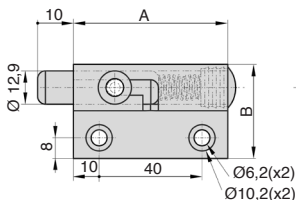

LRR-37-2/ALU

 

LRR-37-1/ALU

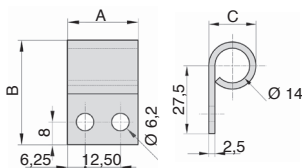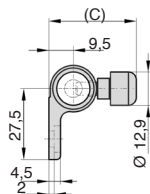

LRR-37-GPV/ALU

### DISCOUNT

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	Type	Weight (g)	Stock*	Price each 1 à 9
<b>Springloaded bolt</b>							
LRR-37-2/ALU	60	36,5	34	2	58		
LRR-37-1/ALU	60	36,5	34	1	58		
<b>Strike</b>							
LRR-37-GPV/ALU	25	37	19	-	11		

\*Depending on availability - Dimensions in mm

## Our other products



INO  
Internal gear, Steel  
20NCD2



SHNbr  
Hexagonal nut  
DIN934, Brass



SSG1\_304L  
Stainless steel spur  
gear, Stainless steel  
304L



RTK  
BoWex® curved tooth  
gear coupling, Nylon  
and steel



CHTRB  
Single and dual  
output gearboxes, Up  
to 53,1 Nm



AT10courroie  
AT type timing belt,  
AT10 Steel cored  
polyurethane



 
PW\_PWG3  
Wheel - precision  
range, Bronze




GAL\_20  
Conveyor roller for  
Ø20mm spindle, Self-  
lubricating polyamide



PO  
Pull handle - Multi-  
sector, Tapped



BLHM20  
Right angled gearbox,  
double output shafts,

 

GLT2-27  
Telescopic drawer  
runners for groove



SMS  
Spiral bevel gear, 1:1

## Complementary products



LRR22  
Small dimension latch  
with locking system,  
Aluminium