

- **Springloaded bolt can be held in unlocked position**

- It is recommended to combine 1 latch with 1 strike

- Materials:


Body: aluminium 6060T5 clear anodised

Shaft and handle: raw aluminium

Cap: Black PE

Spring: Stainless steel


Strike: aluminium 5754 clear anodised

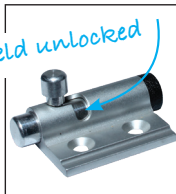


Springloaded bolt





Strike

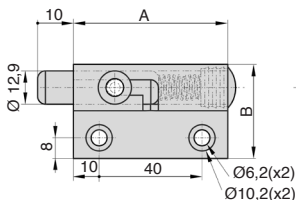

LRR-37-2/ALU

 

LRR-37-1/ALU

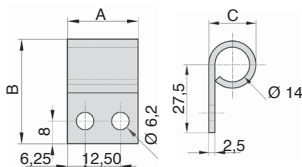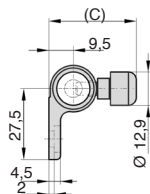

LRR-37-GPV/ALU


DISCOUNT

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	Type	Weight (g)	Stock*	Price each 1 à 9
Springloaded bolt							
LRR-37-2/ALU	60	36,5	34	2	58		
LRR-37-1/ALU	60	36,5	34	1	58		
Strike							
LRR-37-GPV/ALU	25	37	19	-	11		

*Depending on availability - Dimensions in mm

Our other products

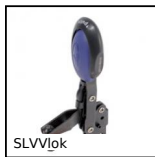

SLVVlok
Vertical toggle clamp,
Vertical toggle clamp /
vertical foot



VEL
Self-gripping cable
strip, electric and
pneumatic cables



INS_SS
Self tapping stainless
steel insert, Stainless
steel



WW16
Drylin® W slide, slide
assembly




CHAL3
Piano hinge, Steel



MDB_MTB
Moulded plastic bevel
gear (nylon), 3:1



 PRF_CHA_D
Hinge and joint, Lift-
off hinge



GPLso
Brush, silk



GAL_42
Guide roller for plate
chain return, Without
...



DIA
Ring operated locking
bolt, with ring



PR105
Articulated foot Ø103,
Ø 103



MEB
Moulded plastic bevel
gear (nylon), 1:1

Complementary products