

Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials : Galvanised steel

Accessory

- Catch plate LRRgpv (tome 5 p.213)

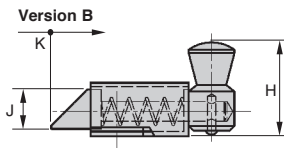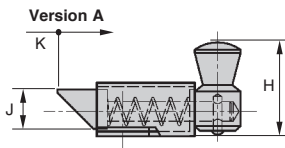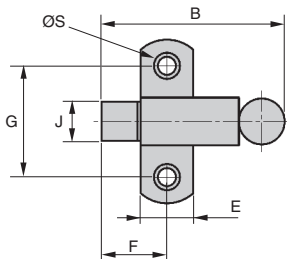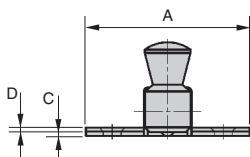

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
Version A															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
Version B															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

*Depending on availability - Dimensions in mm



- Catch for sprung latch LRR

- Materials :

Galvanised steel

Accessory

- Spring loaded latch LRR (tome 5 p.212)

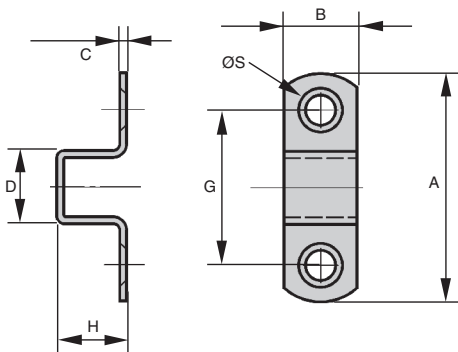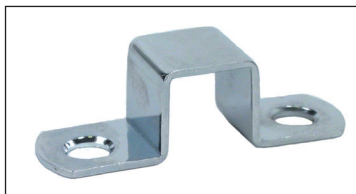


DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock ¹	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €

*Depending on availability - Dimensions in mm

 Our other products



LAT1

1A motorised linear actuator, 1 ampere



FRss

Stainless steel thread inserts, Stainless steel



PR125rehausse

Extension for articulated foot Ø123, articulated foot PR125



HG6

Steel spur gear, Steel 20NCD2



E30

Right angle helical reducers, from 1.50 to 9 Nm



AT5P_AT10P

Connecting plate for AT type timing belts, AT10



BG

Oldham coupling, With set screw



CLG1

Moulded plastic spur gear, Moulded plastic (nylon)



SH1

Parallel axis helical gear, Steel 20NCD2



CHA_GC_14SS

Stainless steel garnet hinge, To screw



RJUM05

Drylin R® linear bearing housing, Closed - Long



PT820

Drive sprocket for slat top chain, Ranges 820 and 815

Complementary products



LRR

Spring loaded latch, Spring loaded latch



LRR-53

Spring loaded latch, Spring return latch - steel



LRR-53

Spring loaded latch, Spring return latch - stainless steel



LRR22

Small dimension system latch with locking system, Aluminium