

Spring loaded latch







LRR

Plated steel

- **Spring return latch**
- Inward/outward opening versions available (A+ B versions)
- Materials :
Galvanised steel

Accessory

- Catch plate LRRGPV (tome 5 p.197)

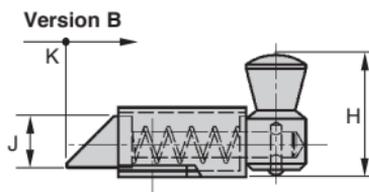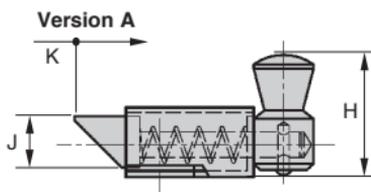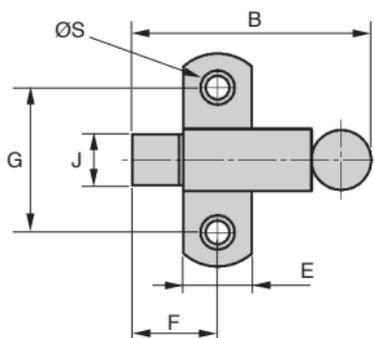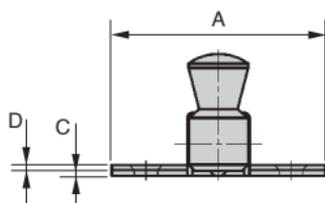

DISCOUNTS

| | | | | |
|------------|-----|-----|------------|-----|
| Qty | 1+ | 10+ | 20+ | 50+ |
| Disc. List | -3% | -5% | On request | |

| Part number | A | B | C | D | E | F | G | H | J | K | ØS | Material | Weight (g) | Price each | |
|------------------|----|----|-----|-----|----|----|----|----|----|----|----|----------|------------|------------|---------|
| | | | | | | | | | | | | | | Stock* | 1 to 9 |
| Version A | | | | | | | | | | | | | | | |
| LRR-50-A/ZN | 50 | 56 | 1,5 | 1,2 | 16 | 20 | 34 | 27 | 12 | 12 | 4 | Steel | 71 | ✓ | 22,27 € |
| Version B | | | | | | | | | | | | | | | |
| LRR-50-B/ZN | 50 | 56 | 1,5 | 1,2 | 16 | 20 | 34 | 27 | 12 | 12 | 4 | Steel | 71 | ✓ | 22,27 € |

*Depending on availability - Dimensions in mm


- Catch for sprung latch LRR

- Materials :

Galvanised steel

Accessory

- Spring loaded latch LRR (tome 5 p.196)

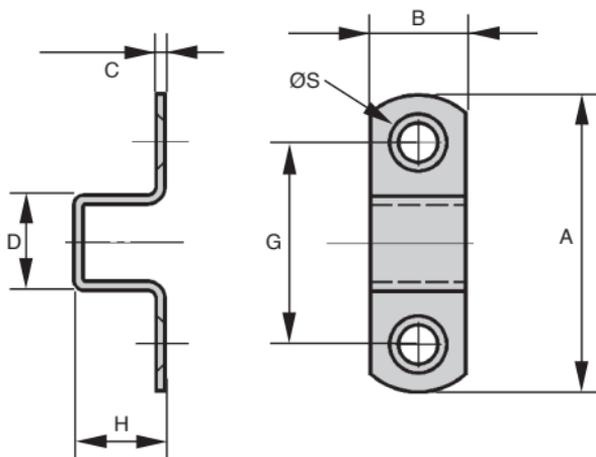

DISCOUNTS

| | | | | |
|------------|-----|-----|------------|-----|
| Qty | 1+ | 10+ | 20+ | 50+ |
| Disc. List | -3% | -5% | On request | |

| Part number | A | B | C | D | G | H | ØS | Material | Weight (g) | Stock [*] | Price each 1 to 9 |
|---------------|----|----|-----|----|----|----|----|----------|------------|--------------------|-------------------|
| LRR-50-GPV/ZN | 50 | 16 | 1,5 | 16 | 34 | 16 | 4 | Steel | 12 | ✓ | 3,26 € |

*Depending on availability - Dimensions in mm

- Slam latches for direct closing in hostile environments

 





- Latch tongue at top
- Resistant to water and cleaning products
- Materials:
Body and support: 304L stainless steel
Latch and handle: 303 stainless steel
Spring: 301 stainless steel

Advantages


- Openings on the top and mounting face allow easy cleaning (no retention of water or dirt)
- No sharp angles (avoids risk of injury)
- Top mounted handle allows easy opening

Applications

- Equipment for the food industry
- Animal breeding (hutches, hen-houses)
- Lids for metal enclosures used in humid environments
- Stainless steel strike plate not supplied

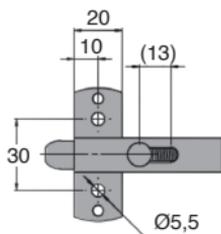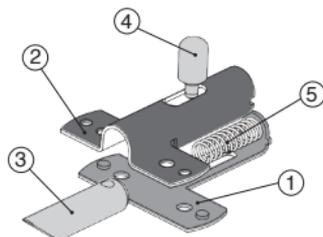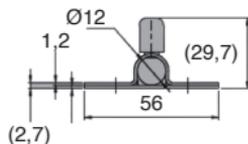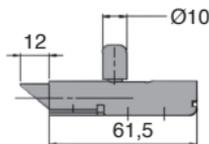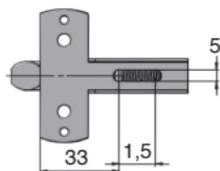

A version

 

B version

DISCOUNTS

| Qty | 1+ | 10+ | 20+ | 50+ |
|-------|------|-----|-----|------------|
| Disc. | List | -3% | -5% | On request |



| Part number | Latch stroke (mm) | Type | Stock* | Price each 1 to 9 |
|-------------|-------------------|-----------|--------|-------------------|
| LRR-56-A/SS | 12 | A version | ✓ | 30,53 € |
| LRR-56-B/SS | 13 | B version | ✓ | 41,68 € |

Dimensions in mm. *Depending on availability


- **Spring loaded single bolt**
- Rolled knot hinge
- Material:
White galvanized steel
Stainless steel 304

Advantages

- Simple locking
- Retractable pivot

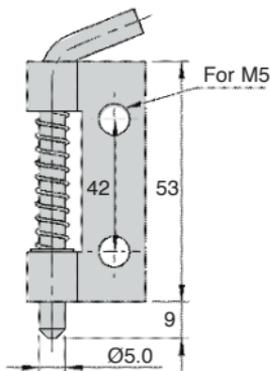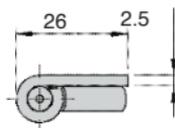

Right handed

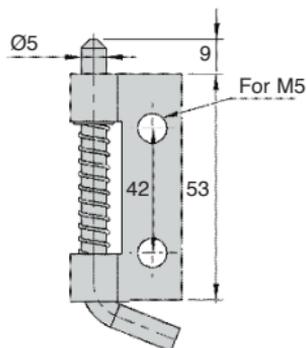

Left handed

DISCOUNTS

| | | | |
|-------|-----|------|------------|
| Qty | 1+ | 50+ | 100+ |
| Disc. | Net | -10% | On request |

| Part number | Version | Stock* | Price each 1 to 49 |
|--------------------------------|---------|--------|-----------------------|
| Steel version | | | |
| LRR-53-26/D | Right | ✓ | 3,25 € |
| LRR-53-26/G | Left | - | 3,25 € |
| Stainless steel version | | | |
| LRR-53-26/G/SS | Left | ✓ | 6,51 € |
| LRR-53-26/D/SS | Right | ✓ | 6,51 € |

*Depending on availability - Dimensions in mm

Small dimension latch with locking system Alu

LRR22


In aluminium

- **Springloaded bolt can be held in unlocked position**

- **Materials:**


Body: aluminium 6060T5 clear anodised
 Shaft and handle: raw aluminium
 Cap: Black PE
 Spring: Stainless steel
 Strike: aluminium 5754 clear anodised

Held unlocked

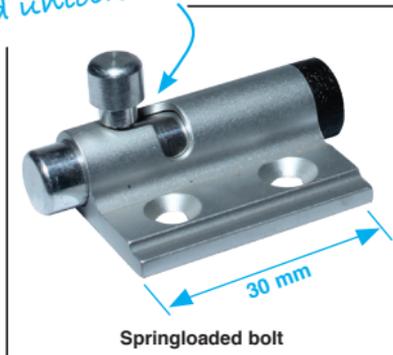


Note


There is no strike for this size

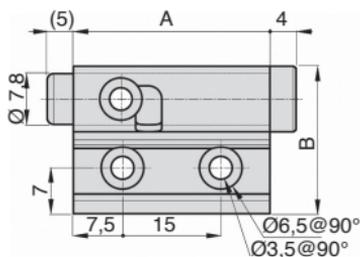

Type 2
LRR-22-2/ALU

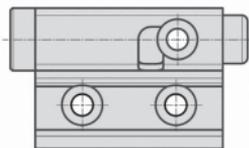

Type 1
LRR-22-1/ALU

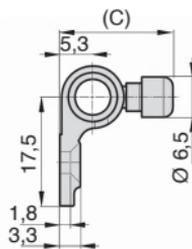

DISCOUNT

| | | | | |
|-------------------|-----|-----|------------|-----|
| Qty | 1+ | 10+ | 20+ | 50+ |
| Disc. List | -3% | -5% | On request | |

| Part number | A | B | C | Type | Weight (g) | Price each 1 to 9 |
|--------------------------|----|------|------|------|------------|-------------------|
| Springloaded bolt | | | | | | |
| LRR-22-2/ALU | 30 | 22,5 | 18,2 | 2 | 9 | 17,19 € |
| LRR-22-1/ALU | 30 | 22,5 | 18,2 | 1 | 9 | 17,19 € |

Dimensions in mm

- **Springloaded bolt can be held in unlocked position**

- It is recommended to combine 1 latch with 1 strike

- Materials:

Body: aluminium 6060T5 clear anodised

Shaft and handle: raw aluminium

Cap: Black PE

Spring: Stainless steel


Strike: aluminium 5754 clear anodised




Springloaded bolt





Strike

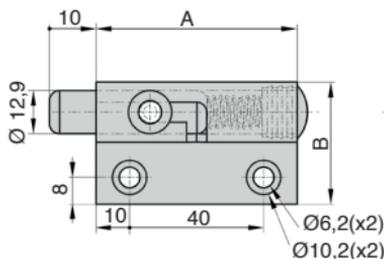

Type 2
LRR-37-2/ALU

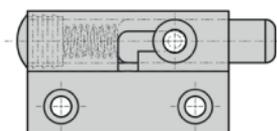

Type 1
LRR-37-1/ALU

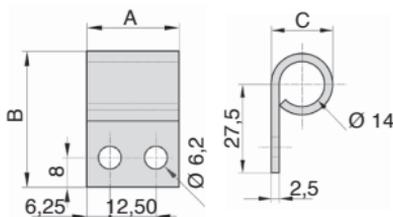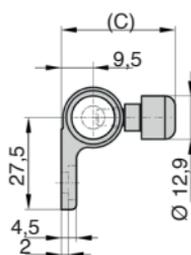

LRR-37-GPV/ALU


DISCOUNT

| | | | | |
|-------|------|-----|-----|------------|
| Qty | 1+ | 10+ | 20+ | 50+ |
| Disc. | List | -3% | -5% | On request |

| Part number | A | B | C | Type | Weight (g) | Price each 1 to 9 |
|--------------------------|----|------|----|------|------------|-------------------|
| Springloaded bolt | | | | | | |
| LRR-37-2/ALU | 60 | 36,5 | 34 | 2 | 58 | 28,02 € |
| LRR-37-1/ALU | 60 | 36,5 | 34 | 1 | 58 | 28,02 € |
| Strike | | | | | | |
| LRR-37-GPV/ALU | 25 | 37 | 19 | - | 11 | 4,96 € |

Dimensions in mm

- Quick closing catch
- Push to close
- Material:
Chromed die cast zinc

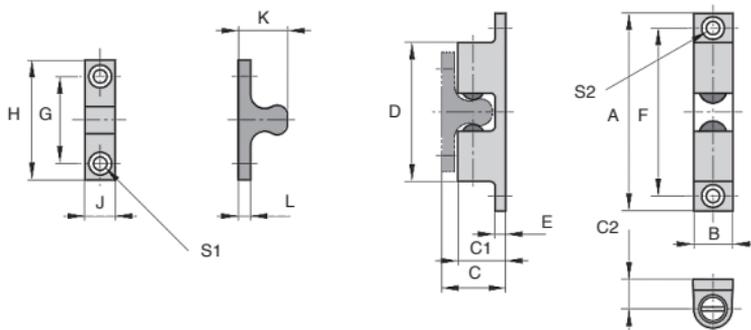

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | C1 | C2 | D | E | F | G |
|--------------|------|------|------|------|------|------|-----|----|----|
| LQT-2B-42-8 | 42,5 | 8,0 | 14,0 | 10,0 | 6,5 | 26,7 | 2,5 | 35 | 16 |
| LQT-2B-50-10 | 50,0 | 10,0 | 16,0 | 12,5 | 7,4 | 29,8 | 3,0 | 40 | 20 |
| LQT-2B-70-13 | 70,0 | 13,5 | 21,2 | 17,0 | 11,0 | 49,0 | 4,0 | 60 | 30 |

| Part number | H | J | K | L | S1 | S2 | Force (N) | Weight (g) | Stock* | Price each 1 to 5 |
|--------------|----|------|------|-----|-----|-----|-----------|------------|--------|-------------------|
| LQT-2B-42-8 | 25 | 7,5 | 11,3 | 2,5 | 3,2 | 3,2 | 30 | 16 | ✓ | 13,80 € |
| LQT-2B-50-10 | 30 | 9,0 | 12,3 | 2,5 | 4,2 | 4,2 | 33 | 26 | ✓ | 16,24 € |
| LQT-2B-70-13 | 42 | 10,5 | 17,2 | 3 | 4,2 | 4,2 | 35 | 70 | ✓ | 28,00 € |

*Depending on availability - Dimensions in mm