

Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials : Galvanised steel

Accessory

- Catch plate LRRgpv (tome 5 p.213)

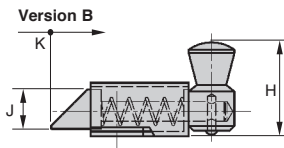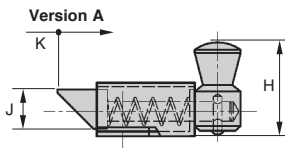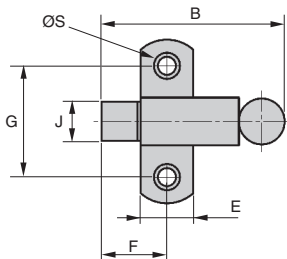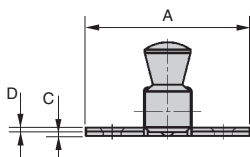

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
Version A															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
Version B															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

*Depending on availability - Dimensions in mm



- Catch for sprung latch LRR

- Materials :

Galvanised steel

Accessory

- Spring loaded latch LRR (tome 5 p.212)

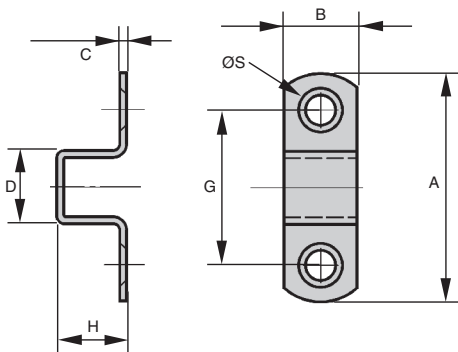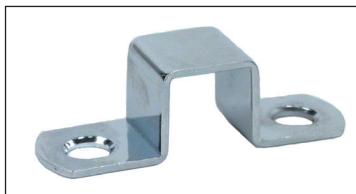

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock ¹	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €

*Depending on availability - Dimensions in mm

Our other products



CHAR5050_Z

Spring hinge, screwed



HSE-HSB

Hexagonal spacer,
Brass



BH02

Single housed bearing
assembly, Bearing
secured with circlips



CHCSS

Socket headed screw,
Stainless steel - A2



PW_PWG3

Worm - precision
range, Stainless steel




TCXR

Automatic chain
tensioner, With steel
sprocket



PSG1

Spur gear - precision
range, Case hardened
steel 20NCD2

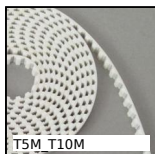

T5M T10M

T type timing belt per
metre, T10 Steel
cored polyurethane



F7-E

Multifunction display,
With external sensor



HRV

V- rail guidance
Simple Select®
system, Rail with



PSPE22

Conical flexible shaft
handlee Ø22, Black
PVC



BABFCFO

Ball pin socket,
Mounting collar with a
round flange

Complementary products



LRR

Spring loaded latch,
Spring loaded latch



LRR-53

Spring loaded latch,
Spring return latch -
steel



LRR-53

Spring loaded latch,
Spring return latch -
stainless steel



SER69K

Quarter turn latch for
the food industry,
Stainless steel