

Spring loaded latch

Stock Bra





LRR

Plated steel

- Spring return latch
- Inward/outward opening versions available (A+ B versions)
- Materials : Galvanised steel

Accessory

- Catch plate LRRgpv (tome 5 p.213)

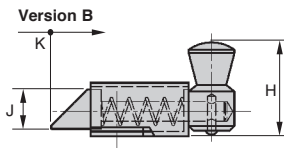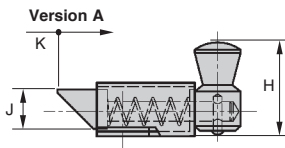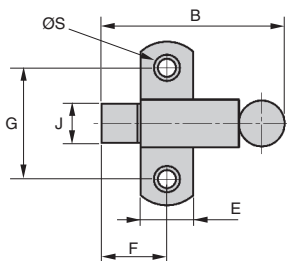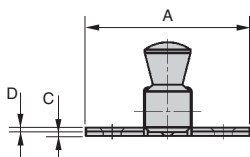

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	E	F	G	H	J	K	ØS	Material	Weight (g)	Price each	
														Stock*	1 to 9
Version A															
LRR-50-A/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €
Version B															
LRR-50-B/ZN	50	56	1,5	1,2	16	20	34	27	12	12	4	Steel	71	✓	21,64 €

*Depending on availability - Dimensions in mm



- Catch for sprung latch LRR

- Materials :

Galvanised steel

Accessory

- Spring loaded latch LRR (tome 5 p.212)

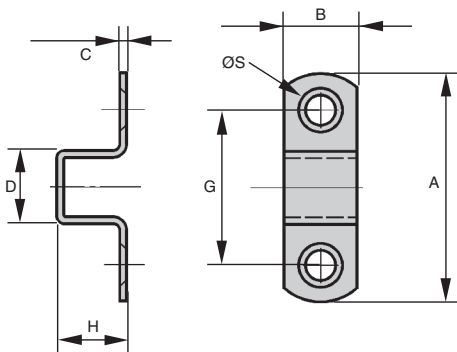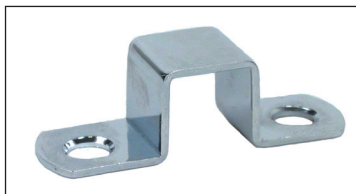

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	C	D	G	H	ØS	Material	Weight (g)	Stock ¹	Price each 1 to 9
LRR-50-GPV/ZN	50	16	1,5	16	34	16	4	Steel	12	✓	3,17 €

*Depending on availability - Dimensions in mm

Our other products



P20
Worm and wheel gear reducer, up to 5 Nm



RDS
Safety washer Hygienic Usit®, Stainless steel



BOX-TOR-C
Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



 
CDPC
Flanged drill bushing, Steel



FBL4004_K32
Brush strip per metre, Black striated polypropylene (PP)



BABA
Ball pin lifting ring, Steel



RPP14
RPP heavy duty timing belt, RPP14



NCT
Square tube connector, Fixed angle



PSG25
Spur gear - precision range, Case hardened steel 20NCD2



SLBS
Stainless steel indexing plunger, Stainless steel



PFC
Fixed rubber levelling foot, Levelling support for small parts



TAC_SS
Stainless steel rigging screw (hook/eye), Stainless steel

Complementary products



LRR
Spring loaded latch, Spring loaded latch



LRR-53
Spring loaded latch, Spring return latch - steel



LRR-53
Spring loaded latch, Spring return latch - stainless steel



LRR22
Small dimension latch with locking system, Aluminium