

LSM

Right hand thread, 1 start

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Stainless steel 316L



Uses

- Lathe drive screws
- Other machine tools

Options

- Available in lengths up to 6000mm (subject to diameter)

stainless steel

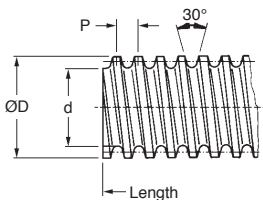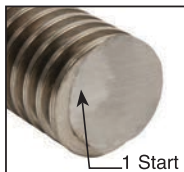

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	5+	10+	
Disc.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	40 to 59**
LSM102	10	2	6,89	0,48	✓	A 52,67 €	A 31,60 €
LSM123	12	3	7,84	0,65	✓	A 39,48 €	A 23,69 €
LSM164	16	4	10,80	1,15	✓	A 66,31 €	A 39,79 €
LSM184	18	4	12,80	1,52	✓	A 84,83 €	A 50,90 €
LSM204	20	4	14,80	1,91	✓	A 103,24 €	A 61,95 €
LSM245	24	5	17,50	2,80	✓	A 146,51 €	A 87,90 €
LSM285	28	5	21,50	3,90	✓	A 212,83 €	A 127,70 €
LSM306	30	6	21,90	4,33	✓	B 147,96 €	B On request
LSM326	32	6	23,90	5,00	✓	B 172,77 €	B On request
LSM366	36	6	27,90	6,55	✓	B 219,45 €	B On request
LSM407	40	7	30,50	8,00	-	B 291,83 €	B On request
LSM508	50	8	39,17	12,76	-	B 454,08 €	B On request

*Depending on availability - Dimensions in mm

** refer to discounts

Left hand thread, 1 start

LSMLH

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e

stainless steel





Uses

- Lathe drive screws
- Other machine tools

Options

- Available in lengths up to 6000mm (subject to diameter)

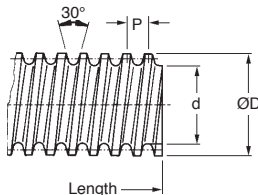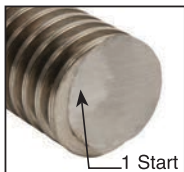

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	5+	10+
Disc.	List	-5%	On request
Lngt.	1000	2000	3000 6000 mm
Price	Uni.	x2,12	x3,18 On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Price each per metre	
					1 to 9	40 to 59**
LSM123/LH	12	3	7,84	0,65	A 64,60 €	A 38,76 €
LSM164/LH	16	4	10,80	1,15	A 83,72 €	A 50,23 €
LSM184/LH	18	4	12,80	1,52	A On request	A On request
LSM204/LH	20	4	14,80	1,91	A 119,10 €	A 71,46 €
LSM245/LH	24	5	17,50	2,80	A 149,30 €	A 89,57 €
LSM285/LH	28	5	21,50	3,90	A On request	A On request
LSM306/LH	30	6	21,90	4,33	B 149,59 €	B On request
LSM326/LH	32	6	23,90	5,00	B 192,52 €	B On request
LSM366/LH	36	6	27,90	6,55	B 209,53 €	B On request
LSM407/LH	40	7	30,50	8,00	B 322,68 €	B On request

*Depending on availability - Dimensions in mm

** refer to discounts

Our other products



PLA

Flat magnet, Flat magnet with threaded hole




HTD8M_20

HTD Heavy duty timing pulley, HTD8 Cast



RDE-N

Sealing washer Hygienic Usit®, Stainless steel - Black EPDM

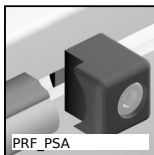

PRF_PSA

Shaft support for aluminium profile, Shaft stop



CHAL3

Piano hinge, Aluminium



ZDB

Machined plastic bevel gear, 2:1



RPCplss

Swivel castor with plate, Stainless steel - Polyamide



DEP

Tools Hygienic Usit® and Hygienic Design®, Protective insert for s...



CM

Tools Hygienic Usit® and Hygienic Design®,



PCS50SS

Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)



RGS

Rotex® GS backlash free jaw coupling, from 0.5 to 190Nm



BAGSS

Stainless steel Clamping collar, Stainless steel

Complementary products



 
BFM

Flanged bronze nut, Bronze - 1 thread



LRM

Trapezoidal bronze nut, Bronze - 1 thread



VKM

Square steel nut, Steel - 1 thread



KSM

Cylindrical steel nut, Steel - 1 thread