

LSM

Right hand thread, 1 start

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Stainless steel 316L



Uses

- Lathe drive screws
- Other machine tools

Options

- Available in lengths up to 6000mm (subject to diameter)

stainless steel

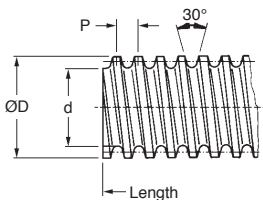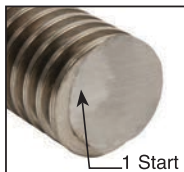

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	5+	10+	
Disc.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	40 to 59**
LSM102	10	2	6,89	0,48	✓	A 52,67 €	A 31,60 €
LSM123	12	3	7,84	0,65	✓	A 39,48 €	A 23,69 €
LSM164	16	4	10,80	1,15	✓	A 66,31 €	A 39,79 €
LSM184	18	4	12,80	1,52	✓	A 84,83 €	A 50,90 €
LSM204	20	4	14,80	1,91	✓	A 103,24 €	A 61,95 €
LSM245	24	5	17,50	2,80	✓	A 146,51 €	A 87,90 €
LSM285	28	5	21,50	3,90	✓	A 212,83 €	A 127,70 €
LSM306	30	6	21,90	4,33	✓	B 147,96 €	B On request
LSM326	32	6	23,90	5,00	✓	B 172,77 €	B On request
LSM366	36	6	27,90	6,55	✓	B 219,45 €	B On request
LSM407	40	7	30,50	8,00	-	B 291,83 €	B On request
LSM508	50	8	39,17	12,76	-	B 454,08 €	B On request

*Depending on availability - Dimensions in mm

** refer to discounts

Left hand thread, 1 start

LSMLH

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e

stainless steel





Uses

- Lathe drive screws
- Other machine tools

Options

- Available in lengths up to 6000mm (subject to diameter)

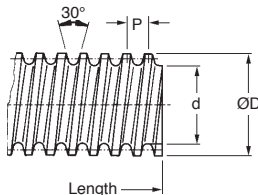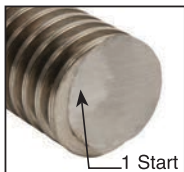

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	5+	10+	
Disc.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Price each per metre	
					1 to 9	40 to 59**
LSM123/LH	12	3	7,84	0,65	A 64,60 €	A 38,76 €
LSM164/LH	16	4	10,80	1,15	A 83,72 €	A 50,23 €
LSM184/LH	18	4	12,80	1,52	A On request	A On request
LSM204/LH	20	4	14,80	1,91	A 119,10 €	A 71,46 €
LSM245/LH	24	5	17,50	2,80	A 149,30 €	A 89,57 €
LSM285/LH	28	5	21,50	3,90	A On request	A On request
LSM306/LH	30	6	21,90	4,33	B 149,59 €	B On request
LSM326/LH	32	6	23,90	5,00	B 192,52 €	B On request
LSM366/LH	36	6	27,90	6,55	B 209,53 €	B On request
LSM407/LH	40	7	30,50	8,00	B 322,68 €	B On request

*Depending on availability - Dimensions in mm


** refer to discounts

Our other products



UGH32

 H Type Guide units,
For Ø32 actuators



QN

Single row cylindrical
roller bearing, Free
outer ring



DCG

Suction cup, 2.5
bellows, nitrile



VDSQ

Sliding lock
adjustment system,
Sliding lock for square
profile



BFM

Flanged bronze nut,
Bronze - 1 thread



UGH50

H Type Guide units,
For Ø50 actuators



LRX

Linear roller slide, Rail
- from 9410 N to
101000 N



 
PLM-C

Cylindrical holding
magnets, Cylindrical
holding magnet



ACM_AZ

Mounting bracket for
bonnet fastener, Hook



CRM

Moulded nylon rack,
Nylon



DOMI120

Domino 120
adjustable slide, Slide
DOMILINE 120



AT10courroie

AT type timing belt,
AT10 Steel cored
polyurethane

Complementary products



 
BFM

Flanged bronze nut,
Bronze - 1 thread




LRM

Trapezoidal bronze
nut, Bronze - 1 thread



VKM

 Square steel nut,
Steel - 1 thread



KSM

Cylindrical steel nut,
Steel - 1 thread