

LSM

Right hand thread, 1 start

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Stainless steel 316L



Uses

- Lathe drive screws
- Other machine tools

Options

- Available in lengths up to 6000mm (subject to diameter)

stainless steel

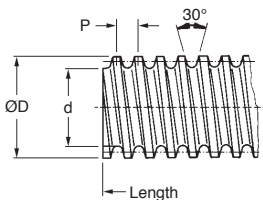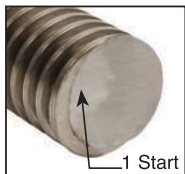

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	5+	10+	
Disc.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	40 to 59**
LSM102	10	2	6,89	0,48	✓	A 52,67 €	A 31,60 €
LSM123	12	3	7,84	0,65	✓	A 39,48 €	A 23,69 €
LSM164	16	4	10,80	1,15	✓	A 66,31 €	A 39,79 €
LSM184	18	4	12,80	1,52	✓	A 84,83 €	A 50,90 €
LSM204	20	4	14,80	1,91	✓	A 103,24 €	A 61,95 €
LSM245	24	5	17,50	2,80	✓	A 146,51 €	A 87,90 €
LSM285	28	5	21,50	3,90	✓	A 212,83 €	A 127,70 €
LSM306	30	6	21,90	4,33	✓	B 147,96 €	B On request
LSM326	32	6	23,90	5,00	✓	B 172,77 €	B On request
LSM366	36	6	27,90	6,55	✓	B 219,45 €	B On request
LSM407	40	7	30,50	8,00	-	B 291,83 €	B On request
LSM508	50	8	39,17	12,76	-	B 454,08 €	B On request

*Depending on availability - Dimensions in mm

** refer to discounts

Left hand thread, 1 start

LSMLH

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e

stainless steel





Uses

- Lathe drive screws
- Other machine tools

Options

- Available in lengths up to 6000mm (subject to diameter)

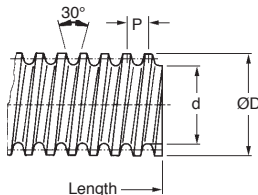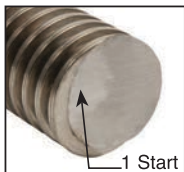

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	5+	10+	
Disc.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Price each per metre	
					1 to 9	40 to 59**
LSM123/LH	12	3	7,84	0,65	A 64,60 €	A 38,76 €
LSM164/LH	16	4	10,80	1,15	A 83,72 €	A 50,23 €
LSM184/LH	18	4	12,80	1,52	A On request	A On request
LSM204/LH	20	4	14,80	1,91	A 119,10 €	A 71,46 €
LSM245/LH	24	5	17,50	2,80	A 149,30 €	A 89,57 €
LSM285/LH	28	5	21,50	3,90	A On request	A On request
LSM306/LH	30	6	21,90	4,33	B 149,59 €	B On request
LSM326/LH	32	6	23,90	5,00	B 192,52 €	B On request
LSM366/LH	36	6	27,90	6,55	B 209,53 €	B On request
LSM407/LH	40	7	30,50	8,00	B 322,68 €	B On request

*Depending on availability - Dimensions in mm

** refer to discounts

Our other products



UCP
Cast iron pillow block bearing, Cast iron




TPEpbd
Castor for aluminium profile, Swivel with brake



PPJ
Indexing plunger with flange, With horizontal mounting flange and pu...



 BLHM60
Right angled gearbox, double output shafts, up to 70 Nm



PTR
Idler chain sprocket, For standard applications



MSP19
Masterplate® glueable insert Ø19/Ø20, Cylindrical with nut



T5M T10M
T type timing belt per metre, T5 Steel cored polyurethane



PSDP18
Flexible tube handle, Black PVC



LRR-53
Spring loaded latch, Spring return latch -



PRF4532
Standard aluminium profile, 45 x 32 mm



SCE
U-shaped cable clamp, Steel



NPTR
Adjustable cross clamp, Adjustable

 
Complementary products



BFM
Flanged bronze nut, Bronze - 1 thread



LRM
Trapezoidal bronze nut, Bronze - 1 thread



VKM
Square steel nut, Steel - 1 thread



KSM
Cylindrical steel nut, Steel - 1 thread