

## LSM

## Right hand thread, 1 start

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Stainless steel 316L



### Uses

- Lathe drive screws
- Other machine tools

### Options

- Available in lengths up to 6000mm (subject to diameter)

stainless steel

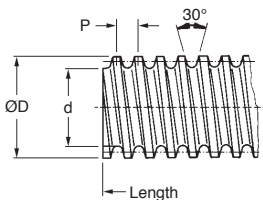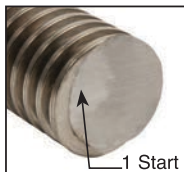

### A DISCOUNTS and AVAILABLE LENGTHS

| Qty   | 1+   | 10+   | 20+   | 40+        |
|-------|------|-------|-------|------------|
| Disc. | List | -30%  | -40%  | On request |
| Lngt. | 1000 | 2000  | 3000  | 6000 mm    |
| Price | Uni. | x2,12 | x3,18 | On request |

### B DISCOUNTS and AVAILABLE LENGTHS

| Qty   | 1+   | 5+    | 10+        |            |
|-------|------|-------|------------|------------|
| Disc. | List | -5%   | On request |            |
| Lngt. | 1000 | 2000  | 3000       | 6000 mm    |
| Price | Uni. | x2,12 | x3,18      | On request |

| Part number | ØD | Pitch<br>P (mm) | d<br>mini. | Weight<br>(kg/m) | Stock* | Price each per metre |              |
|-------------|----|-----------------|------------|------------------|--------|----------------------|--------------|
|             |    |                 |            |                  |        | 1 to 9               | 40 to 59**   |
| LSM102      | 10 | 2               | 6,89       | 0,48             | ✓      | A 52,67 €            | A 31,60 €    |
| LSM123      | 12 | 3               | 7,84       | 0,65             | ✓      | A 39,48 €            | A 23,69 €    |
| LSM164      | 16 | 4               | 10,80      | 1,15             | ✓      | A 66,31 €            | A 39,79 €    |
| LSM184      | 18 | 4               | 12,80      | 1,52             | ✓      | A 84,83 €            | A 50,90 €    |
| LSM204      | 20 | 4               | 14,80      | 1,91             | ✓      | A 103,24 €           | A 61,95 €    |
| LSM245      | 24 | 5               | 17,50      | 2,80             | ✓      | A 146,51 €           | A 87,90 €    |
| LSM285      | 28 | 5               | 21,50      | 3,90             | ✓      | A 212,83 €           | A 127,70 €   |
| LSM306      | 30 | 6               | 21,90      | 4,33             | ✓      | B 147,96 €           | B On request |
| LSM326      | 32 | 6               | 23,90      | 5,00             | ✓      | B 172,77 €           | B On request |
| LSM366      | 36 | 6               | 27,90      | 6,55             | ✓      | B 219,45 €           | B On request |
| LSM407      | 40 | 7               | 30,50      | 8,00             | -      | B 291,83 €           | B On request |
| LSM508      | 50 | 8               | 39,17      | 12,76            | -      | B 454,08 €           | B On request |

\*Depending on availability - Dimensions in mm

\*\* refer to discounts

Left hand thread, 1 start

LSMLH

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e

stainless steel





## Uses

- Lathe drive screws
- Other machine tools

## Options

- Available in lengths up to 6000mm (subject to diameter)

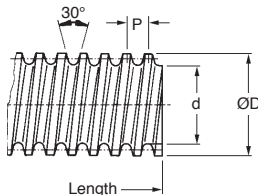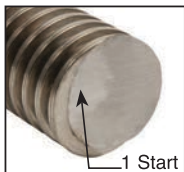

## A DISCOUNTS and AVAILABLE LENGTHS

|       |      |       |       |            |
|-------|------|-------|-------|------------|
| Qty   | 1+   | 10+   | 20+   | 40+        |
| Disc. | List | -30%  | -40%  | On request |
| Lngt. | 1000 | 2000  | 3000  | 6000 mm    |
| Price | Uni. | x2,12 | x3,18 | On request |

## B DISCOUNTS and AVAILABLE LENGTHS

|       |      |       |                  |
|-------|------|-------|------------------|
| Qty   | 1+   | 5+    | 10+              |
| Disc. | List | -5%   | On request       |
| Lngt. | 1000 | 2000  | 3000 6000 mm     |
| Price | Uni. | x2,12 | x3,18 On request |

| Part number | ØD | Pitch P (mm) | d mini. | Weight (kg/m) | Price each per metre |              |
|-------------|----|--------------|---------|---------------|----------------------|--------------|
|             |    |              |         |               | 1 to 9               | 40 to 59**   |
| LSM123/LH   | 12 | 3            | 7,84    | 0,65          | A 64,60 €            | A 38,76 €    |
| LSM164/LH   | 16 | 4            | 10,80   | 1,15          | A 83,72 €            | A 50,23 €    |
| LSM184/LH   | 18 | 4            | 12,80   | 1,52          | A On request         | A On request |
| LSM204/LH   | 20 | 4            | 14,80   | 1,91          | A 119,10 €           | A 71,46 €    |
| LSM245/LH   | 24 | 5            | 17,50   | 2,80          | A 149,30 €           | A 89,57 €    |
| LSM285/LH   | 28 | 5            | 21,50   | 3,90          | A On request         | A On request |
| LSM306/LH   | 30 | 6            | 21,90   | 4,33          | B 149,59 €           | B On request |
| LSM326/LH   | 32 | 6            | 23,90   | 5,00          | B 192,52 €           | B On request |
| LSM366/LH   | 36 | 6            | 27,90   | 6,55          | B 209,53 €           | B On request |
| LSM407/LH   | 40 | 7            | 30,50   | 8,00          | B 322,68 €           | B On request |

\*Depending on availability - Dimensions in mm

\*\* refer to discounts

## Our other products



**BAGtr**  
Lead screw clamping collar, Aluminium



**E15**  
Right angle helical reducers, from 0.40 to 2.53 Nm



 
**HAS**  
Captive C washer, Slotted flat headed shoulder screw



**ACLEPP**  
Right angled bracket for aluminium profile, 4 holes



**DOMI\_MD**  
Domino rotary table, 40/1



**BLHM50**  
Right angled gearbox, double output shafts, up to 30 Nm




**CHMR30**  
Worm and wheel gear reducer, up to 28 Nm




**BOX-SHNA**  
Hexagonal nut - DIN934, Box set of steel nuts



 
**HTD8M\_30**  
HTD Heavy duty timing pulley, HTD8 Cast



**B**  
Steel bevel gear, 1:1

 

**DP**  
Dowel pin, Solid ISO 2338

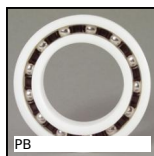

**PB**  
Plastic deep groove ball bearing, Plastic - balls material : staine...


## Complementary products



 
**BFM**  
Flanged bronze nut, Bronze - 1 thread



**LRM**  
Trapezoidal bronze nut, Bronze - 1 thread



**VKM**  
Square steel nut, Steel - 1 thread

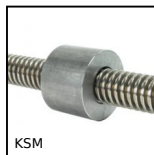

**KSM**  
Cylindrical steel nut, Steel - 1 thread