

Universal joint cover


Industrial range

M

- Bellows for single joints
- For double joints, use two covers

Advantages

- The use of a cover can extend the operating life of a universal joint 5 times

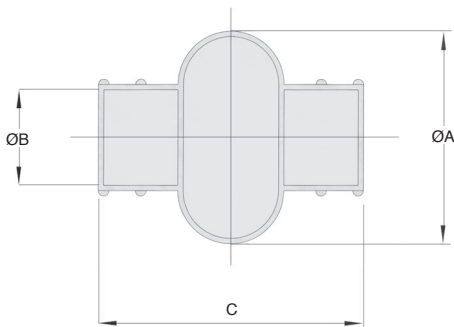

DISCOUNTS

Qty	1+	2+	4+	10+
Disc. List	-6%	-12%	On request	

Part number	Joint bore-size (approx)	ØA	ØB	C	For universal joint n°	Stock*	Price each
						✓	€
M03-A-10	10	39	20,5	47	G03 GD03 H03 HD03 CT10	✓	9,75 €
M04-A-12	12	47	24,5	52	G04 GD04 H04 HD04 CT12	✓	9,75 €
M05-A-14	14	51	27,5	58	G05 GD05 H05 HD05 CT14	✓	9,75 €
M1-A-16	16	56	30,5	67	G1 GD1 H1 HD1 CT16	✓	10,67 €
M2-A-18	18	66	35,5	74	G2 GD2 H2 HD2 CT18	✓	10,67 €
M3-A-20	20	75	40,0	84	G3 GD3 H3 HD3 CT20	✓	15,26 €
M4-A-22	22	83	45,0	97	G4 GD4 H4 HD4 CT22	✓	15,26 €
M5-A-25	25	93	50,0	110	G5 GD5 H5 HD5 CT25	✓	16,56 €
M6-A-30	30	105	56,0	124	G6 GD6 H6 HD6 CT30	✓	16,56 €

*Depending on availability - Dimensions in mm

Our other products



PTA40

Articulated foot with
solid base foot Ø 40,
30000N



PCLA_T

Technopolymer
clamping lever - male,
Plastic



PRF_PA

Angle plate for
aluminium profile,
Adjustable plate



SLB

Indexing plunger,
steel class 5.8



EFTC

Fixing support,
Stainless steel



SER

Magnetic doorstop for
aluminium profile,
Magnetic doorstop



ACLEPP

Right angled bracket
for aluminium profile,
4 holes



PGT

Sliding profile, Sliding
panel support



SA_SAKH

Housing for linear
bearing, Closed - light



ACLRP

Wheel for aluminium
profile, Integrated



CHA60

Rectangular hinge,
drilled or countersunk,



FIRSTDC1Q60

Speed controller 10A,
10 A

Complementary products




G01

Single universal joint,
Normal duty



GD01

 Double universal joint,
Standard duty



CT

Telescopic universal
joint, Normal duty



CTss

Universal joint,
telescopic, Inox, Light
duty