

Universal joint cover


Industrial range

M

- Bellows for single joints
- For double joints, use two covers

Advantages

- The use of a cover can extend the operating life of a universal joint 5 times

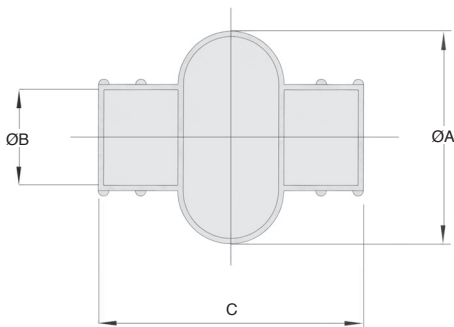

DISCOUNTS

Qty	1+	2+	4+	10+
Disc. List	-6%	-12%	On request	

Part number	Joint bore-size (approx)	ØA	ØB	C	For universal joint n°	Stock*	Price each
						✓	€
M03-A-10	10	39	20,5	47	G03 GD03 H03 HD03 CT10	✓	9,75 €
M04-A-12	12	47	24,5	52	G04 GD04 H04 HD04 CT12	✓	9,75 €
M05-A-14	14	51	27,5	58	G05 GD05 H05 HD05 CT14	✓	9,75 €
M1-A-16	16	56	30,5	67	G1 GD1 H1 HD1 CT16	✓	10,67 €
M2-A-18	18	66	35,5	74	G2 GD2 H2 HD2 CT18	✓	10,67 €
M3-A-20	20	75	40,0	84	G3 GD3 H3 HD3 CT20	✓	15,26 €
M4-A-22	22	83	45,0	97	G4 GD4 H4 HD4 CT22	✓	15,26 €
M5-A-25	25	93	50,0	110	G5 GD5 H5 HD5 CT25	✓	16,56 €
M6-A-30	30	105	56,0	124	G6 GD6 H6 HD6 CT30	✓	16,56 €

*Depending on availability - Dimensions in mm

Our other products



NK27

Drylin®N miniature guiding system, Width 27 mm



BIM

Indexing plunger mini, miniature



PHTss

Pull handle, Up to 250 °C



UTKswr

Utilitak® V rail, V rail



BTE

Universal tension arm, For standard applications



CABma

Swaging sleeve for fitting cable, To crimp a wire rope



NCT

Square tube connector, Fixed angle



PTA40ssEB

Articulated foot with sheet metal base Ø40, Ø 40



J64

Spur gear coaxial gearbox, from 0.57 to



BPTR

End cap for round tube, Standard



HTD8M_20

HTD Heavy duty timing pulley, HTD8



CABtool

Fitting cable tools, Crimping tools

Complementary products




G01

Single universal joint, Normal duty



GD01

 Double universal joint, Standard duty



CT

Telescopic universal joint, Normal duty



CTss

Universal joint, telescopic, Inox, Light duty