


- Type C Carabiner
- White zinc plated steel
- Product carries no certification marking

Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

Info

- Not suitable for climbing
- Also exists in stainless steel

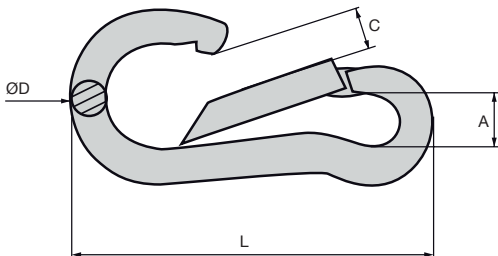

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	L	A	C	SWL (kg)	Weight (g)	Stock*	Price each 1 to 19
MAC5-50	5	50	8	7	50	16	✓	1,47 €
MAC6-60	6	60	8	8	90	26	✓	1,66 €
MAC7-70	7	70	11	9	150	44	✓	2,26 €
MAC8-80	8	80	12	10	190	62	✓	2,29 €
MAC9-90	9	90	13	11	230	92	-	2,53 €
MAC10-100	10	100	16	13	310	126	-	3,05 €
MAC11-120	11	120	19	17	340	192	-	3,80 €
MAC12-140	12	140	20	19	380	256	-	5,16 €

Dimensions in mm

Our other products



BSP

Compact precision slide, from 156 N to 980 N



BEK

Bearing housing for miniature ballscrew, Bearing housing



PENV

Recessed handle, screw fixing



PRES3HR

Manual workbench press, Force up to 400kg



CHTRP

Single and dual output gearboxes, Up to 34,5 Nm



BIM

Indexing plunger mini, miniature



GAL_20

Conveyor roller for Ø20mm spindle, Self-lubricating polyamide



 
DEP

Tools Hygienic Usit® and Hygienic Design®, Protective insert for s...



RTK

BoWex® curved tooth gear coupling, Nylon and steel



BPF

Sheet steel flanged bearing for light loads, Sheet steel



SLHHlok

Horizontal toggle clamp, Horizontal toggle clamp /



QNUP

Single row cylindrical roller bearing, 1 fixed inner flange and 1 fr...

Complementary products



MACss

Stainless steel carabiner, Stainless steel