


- Type C Carabiner
- White zinc plated steel
- Product carries no certification marking

### Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

### Info

- Not suitable for climbing
- Also exists in stainless steel

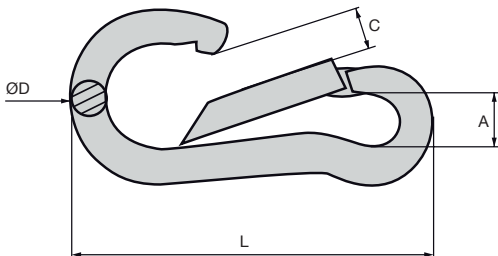

### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	L	A	C	SWL (kg)	Weight (g)	Stock*	Price each 1 to 19
MAC5-50	5	50	8	7	50	16	✓	1,47 €
MAC6-60	6	60	8	8	90	26	✓	1,66 €
MAC7-70	7	70	11	9	150	44	✓	2,26 €
MAC8-80	8	80	12	10	190	62	✓	2,29 €
MAC9-90	9	90	13	11	230	92	-	2,53 €
MAC10-100	10	100	16	13	310	126	-	3,05 €
MAC11-120	11	120	19	17	340	192	-	3,80 €
MAC12-140	12	140	20	19	380	256	-	5,16 €

Dimensions in mm

## Our other products



PSPD18

Flexible tube handle,  
Black PVC



LVT

Miniature motorised  
actuator 4A, 4 ampers



RFV50

Stainless steel worm  
and wheel gearbox,  
up to 80 Nm



G4-ECO

Eco range Spur gear,  
Steel C45



BOXdhx

Boxed set of threaded  
dowel pins DIN7979D,  
Boxed set -  
extractable D...



TRMSS

Spur round rack,  
Stainless steel -  
module 1-5



F7-I

Multifunction display,  
With internal sensor



ASH

Hoist ring for welding,  
for straight lifts - for  
welding



PCS50

Chain sprocket - steel,  
12.7mm (DIN08B-1)



ACL-PLAngle

Joining plate for  
aluminium profile,



M0

Worm and wheel set,  
Unhardened steel



PTGP

Tensioner pulley, For  
flat belts

## Complementary products



MACss

Stainless steel  
carabiner, Stainless  
steel