


- Type C Carabiner
- White zinc plated steel
- Product carries no certification marking

### Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

### Info

- Not suitable for climbing
- Also exists in stainless steel

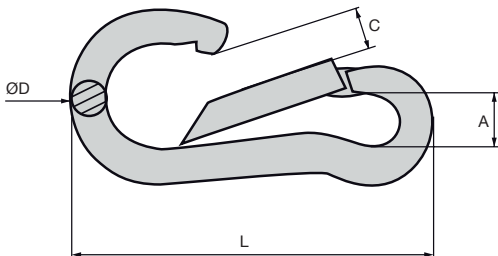

### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

 
Part number	ØD	L	A	C	SWL (kg)	Weight (g)	Stock*	Price each 1 to 19
MAC5-50	5	50	8	7	50	16	✓	1,47 €
MAC6-60	6	60	8	8	90	26	✓	1,66 €
MAC7-70	7	70	11	9	150	44	✓	2,26 €
MAC8-80	8	80	12	10	190	62	✓	2,29 €
MAC9-90	9	90	13	11	230	92	-	2,53 €
MAC10-100	10	100	16	13	310	126	-	3,05 €
MAC11-120	11	120	19	17	340	192	-	3,80 €
MAC12-140	12	140	20	19	380	256	-	5,16 €

Dimensions in mm

## Our other products



ACLEFS  
Floor anchor for  
aluminium profile,  
Standard



T0  
Torsion spring,  
Stainless steel



CFES  
Eccentric cam  
follower, Eccentric



SEH  
Horizontal stirrup  
toggle clamp,  
Horizontal Latch  
clamp - stainless ...




CCLSS  
Stainless steel wire  
thimble, Stainless  
steel



PFC  
Fixed rubber levelling  
foot, Levelling support  
for small parts



M0  
Worm and wheel set,  
Bronze

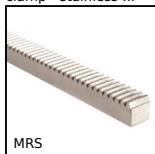


MRS  
Stainless steel metric  
section rack, Stainless  
steel



DOG319  
Motor-gearbox 12V  
and 24V DC, from 4 to  
9 Nm



 NCT  
Square tube  
connector, Fixed  
angle



KS  
Keysteel, Stainless  
steel - Keystick



BSCm  
Knurled torque knobs  
- male, Knurled  
threaded torque

## Complementary products



MACss  
Stainless steel  
carabiner, Stainless  
steel