


- Type C Carabiner
- White zinc plated steel
- Product carries no certification marking

### Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

### Info

- Not suitable for climbing
- Also exists in stainless steel

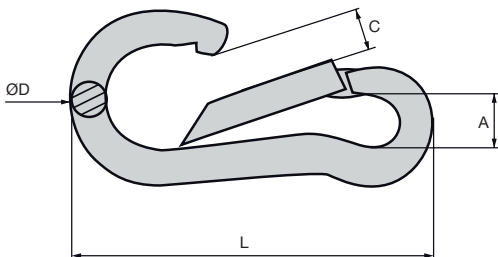


### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	L	A	C	SWL (kg)	Weight (g)	Stock*	Price each 1 to 19
MAC5-50	5	50	8	7	50	16	✓	1,47 €
MAC6-60	6	60	8	8	90	26	✓	1,66 €
MAC7-70	7	70	11	9	150	44	✓	2,26 €
MAC8-80	8	80	12	10	190	62	✓	2,29 €
MAC9-90	9	90	13	11	230	92	-	2,53 €
MAC10-100	10	100	16	13	310	126	-	3,05 €
MAC11-120	11	120	19	17	340	192	-	3,80 €
MAC12-140	12	140	20	19	380	256	-	5,16 €

Dimensions in mm
 
## Our other products



Tools, Assembly key



Parallel axis helical gear - Precision range, 20NCD2 case hardened steel



Ground spur gear, Heat treated steel



Multifunction display, Right angled mounting bracket



 
Indexing plunger, With grip - Stainless steel



Indexing plunger, steel class 5.8




Thermoplastic T handle, With threaded spindle



Roller for aluminium profile, Shaft stop



 Bevel gear - Steel C43, 2:1



Support brush, Tube Ø28



Flange bearing, Stainless steel



Worm - precision range, Steel

## Complementary products



Carabiner, Stainless steel