

Metal diameter 5 to 12mm

MACss


- Type C Carabiner
- Stainless steel 316
- Product carries no certification marking

Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

Info

- Not suitable for climbing
- Also exists in steel

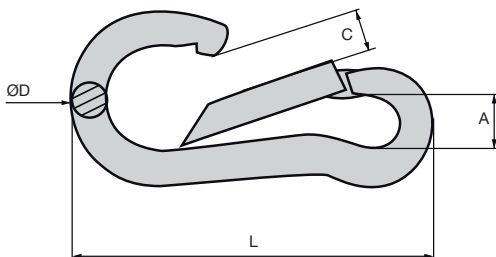

INCREASED STOCK

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	D	L	A	C	SWL (kg)	Weight (g)	Stock*	Price each 1 to 19
MAC5-50/SS	5	50	8	7	90	16	✓	3,74 €
MAC6-60/SS	6	60	8	8	150	28	✓	4,47 €
MAC7-70/SS	7	70	10	9	180	43	✓	6,28 €
MAC8-80/SS	8	80	12	11	225	66	✓	7,14 €
MAC10-100/SS	10	100	14	14	375	129	✓	10,17 €
MAC11-120/SS	11	120	19	17	390	186	-	13,37 €
MAC12-140/SS	12	140	23	21	410	260	-	18,43 €

Dimensions in mm

Our other products



MEB

Moulded plastic bevel gear (nylon), 1:1



HLUMss

Revolving handle for handwheel, Stainless steel 316



CHAR16Q46

Spring hinge, screwed



PRF_PA

Angle plate for aluminium profile, Adjustable plate



PTCR

Adjustable furniture foot, square tube



MFB_MHB

Moulded plastic bevel gear (nylon), 4:1



NT121

Spur gear coaxial gearbox, from 20 to 68 Nm - In-line



WSS

Symmetrical S shaped hook, Steel



BPM-Z

Plastic slotted spring plunger with ball tip, Plastic body +



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



BMM

Knurled knob - male, Knurled



SSG1

Stainless steel spur gear, Stainless steel 304L

Complementary products



PPCss

Pad eye on mounting plate squarred, Stainless steel