

Metal diameter 5 to 12mm

MACss


- Type C Carabiner
- Stainless steel 316
- Product carries no certification marking

Application

- The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

Info

- Not suitable for climbing
- Also exists in steel

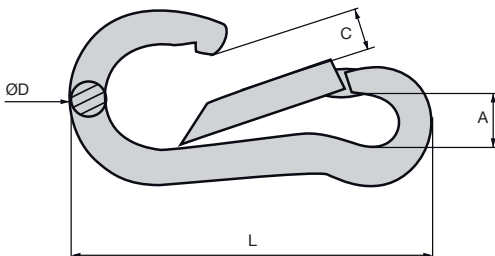

INCREASED STOCK

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	D	L	A	C	SWL (kg)	Weight (g)	Stock*	Price each 1 to 19
MAC5-50/SS	5	50	8	7	90	16	✓	3,74 €
MAC6-60/SS	6	60	8	8	150	28	✓	4,47 €
MAC7-70/SS	7	70	10	9	180	43	✓	6,28 €
MAC8-80/SS	8	80	12	11	225	66	✓	7,14 €
MAC10-100/SS	10	100	14	14	375	129	✓	10,17 €
MAC11-120/SS	11	120	19	17	390	186	-	13,37 €
MAC12-140/SS	12	140	23	21	410	260	-	18,43 €

Dimensions in mm

Our other products



DOMI120

Accessories, Turntable



 
PCP

Cell carrier assembly,
Ready assembled



GMK17_R

Round guide, Round
guide for conical
profile



SLS

Bearing block for
leadscrew, Fixed
Drylin® bearing block



SUPCC

Self-centering
clamping hub steel,
With lock nut



T10courroie

T type timing belt,
T10 Steel cored
polyurethane



SSB

Stainless steel bevel
gear, 1:1



PM3

Worm and wheel set,
Non hardened steel



MAC

Carabiner DIN5299
steel, Steel



BL8

Right angled gearbox,
from 0.20 to 2 Nm



AT5M AT10M

AT type timing belt
per metre, AT10 Steel



SH3

Parallel axis helical
gear, Steel 20NCD2

Complementary products



PPC_{SS}

Pad eye on mounting
plate squarred,
Stainless steel