


MAX22 Torque from 0.07 to 0.2 Nm


- Type of gearbox: spur gear
- Bearings: self lubricating bushes
- Avg angular backlash: 2° to 3°
- Max axial load: 15N
- Max radial load at 5 mm from fixing surface: 35 N
- Working temperature: -5 to 65 °C
- Weight: 104g min

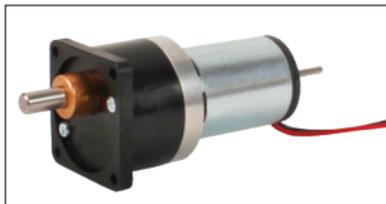

Accessories

- ESCON-4Q-50/5 (servo-amplifier, tome 2 p.284)
- NANODC-1Q-30/3 (speed controller, tome 2 p.282)
- Power supplies: ALIDR30-12 and ALIDR30-24 (tome 2 p.280)

Replaces the MAX30

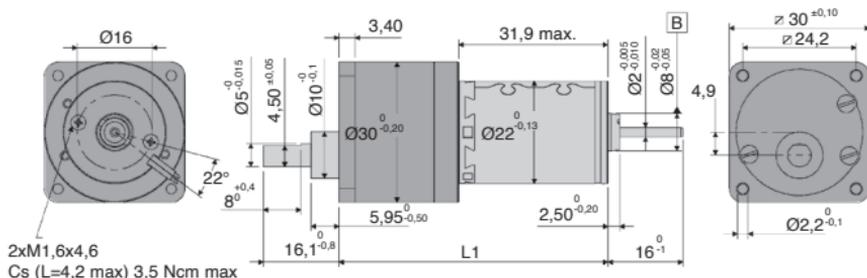

Wire length: 150 mm ±5
Stripped and tinned ends: 4 mm ±1

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-7%	On request	

Part number	Ratio	N° of stages	Efficiency	L1 (mm)	No-load speed (rpm)	Speed under load (rpm)	Nominal torque (Nm)	Nominal current (A)	Price each 1 to 5
12 V version									
MAX22-12-015	15:1	3	73%	54,9	356	176	0,07	0,30	251,54 €
MAX22-12-100	100:1	4	66%	57,4	53	47	0,10	0,08	290,77 €
MAX22-12-200	200:1	5	59%	62,4	27	23	0,20	0,09	300,58 €
24 V version									
MAX22-24-015	15:1	3	73%	54,9	435	252	0,07	0,18	251,54 €
MAX22-24-100	100:1	4	66%	57,4	65	58	0,10	0,05	293,30 €
MAX22-24-200	200:1	5	59%	62,4	33	29	0,20	0,05	300,58 €

Dimensions in mm

