


Motor-gearbox, 12 and 24 V DC

MAX22 Torque from 0.07 to 0.2 Nm


- Type of gearbox: spur gear
- Bearings: self lubricating bushes
- Avg angular backlash: 2° to 3°
- Max axial load: 15N
- Max radial load at 5 mm from fixing surface: 35 N
- Working temperature: -5 to 65 °C
- Weight: 104g min

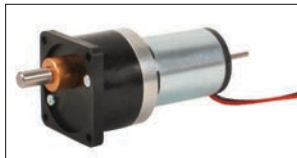

Accessories

- ESCON-4Q-50/5 (servo-amplifier)
- NANODC-1Q-30/3 (speed controller)
- Power supplies: ALIDR30-12 and ALIDR30-24

Replaces the MAX30

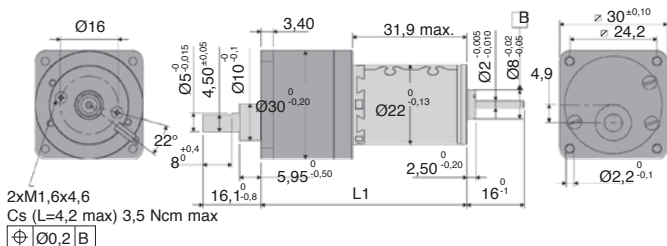

Wire length: 150 mm ±5
Stripped and tinned ends: 4 mm ±1

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-7%	On request	

Part number	Ratio	N° of stages	Efficiency	L1 (mm)	No-load speed (rpm)	Speed under load (rpm)	Nominal torque (Nm)	Nominal current (A)	Price each 1 to 5
12 V version									
MAX22-12-015	15:1	3	73%	54,9	356	176	0,07	0,30	161,00 €
MAX22-12-100	100:1	4	66%	57,4	53	47	0,10	0,08	186,09 €
MAX22-12-200	200:1	5	59%	62,4	27	23	0,20	0,09	192,36 €
24 V version									
MAX22-24-015	15:1	3	73%	54,9	435	252	0,07	0,18	161,00 €
MAX22-24-100	100:1	4	66%	57,4	65	58	0,10	0,05	164,26 €
MAX22-24-200	200:1	5	59%	62,4	33	29	0,20	0,05	192,36 €

Dimensions in mm

Our other products



Steel spur gear, Steel 20NCD2



 
Stainless steel wire thimble, Stainless steel



Lead screw clamping collar, Aluminium



Steel spur gear, Steel 20NCD2



Worm and wheel set, Machined plastic (delrin)



Articulated fixable foot with pressed base Ø100, Ø 100



Stainless steel rigging screw (hook/hook), Stainless steel



Spur gear - precision range, Stainless steel 316



Female wing knob, Fully threaded



Flanged drill bushing, Steel



Wheel - precision range, Bronze



Base plate for aluminium profile, Base plate

Complementary products



Speed controller 5A, 5 A



Speed controller 3A, 3 A