


Motor-gearbox, 12 and 24 V DC

MAX22 Torque from 0.07 to 0.2 Nm


- Type of gearbox: spur gear
- Bearings: self lubricating bushes
- Avg angular backlash: 2° to 3°
- Max axial load: 15N
- Max radial load at 5 mm from fixing surface: 35 N
- Working temperature: -5 to 65 °C
- Weight: 104g min

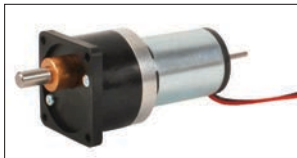

Accessories

- ESCON-4Q-50/5 (servo-amplifier)
- NANODC-1Q-30/3 (speed controller)
- Power supplies: ALIDR30-12 and ALIDR30-24

Replaces the MAX30

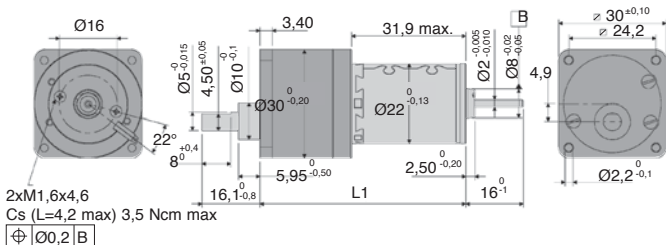

Wire length: 150 mm \pm 5

Stripped and tinned ends: 4 mm \pm 1


DISCOUNTS

Qty	1+	6+	10+
Disc. List	-7%	On request	

Part number	Ratio	N° of stages	Efficiency	L1 (mm)	No-load speed (rpm)	Speed under load (rpm)	Nominal torque (Nm)	Nominal current (A)	Price each 1 to 5
12 V version									
MAX22-12-015	15:1	3	73%	54,9	356	176	0,07	0,30	161,00 €
MAX22-12-100	100:1	4	66%	57,4	53	47	0,10	0,08	186,09 €
MAX22-12-200	200:1	5	59%	62,4	27	23	0,20	0,09	192,36 €
24 V version									
MAX22-24-015	15:1	3	73%	54,9	435	252	0,07	0,18	161,00 €
MAX22-24-100	100:1	4	66%	57,4	65	58	0,10	0,05	164,26 €
MAX22-24-200	200:1	5	59%	62,4	33	29	0,20	0,05	192,36 €

Dimensions in mm


Our other products

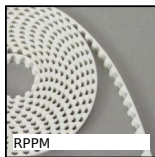

RPPM
RPP type belt per metre, RPP8 Steel cored polyurethane



GLP
Small 6 lobe threaded handle - male, Technopolymer - Steel

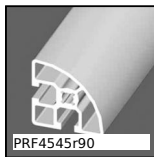

PRF4545r90
Standard aluminium profile, 45 x 45 mm - R90°



RIMple
Locking castor, with mounting plate



AC
Strike for toggle latch, 13mm



BOXKK
Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



NK17
Drylin®N miniature guiding system, Width 17 mm



CAP815
Slim slat top chain stainless steel, Narrow range 815



FBL4004_K32
Brush strip per metre, Black striated



ACL-APB
Closing system for aluminium profile,



HK
Manual locking clamp, Manual locking clamp



GE_ES_2RS
Spherical bushing, Steel / steel with seals

Complementary products



ESCON
Speed controller 5A, 5 A



NANO
Speed controller 3A, 3 A