

Hexagonal ended handle

For use with manually operated bevel gearbox


MBEX

- Handle for operating RAM and RVM manual bevel gearboxes

- Material

Shaft: stainless steel

Rotating handle: plastic

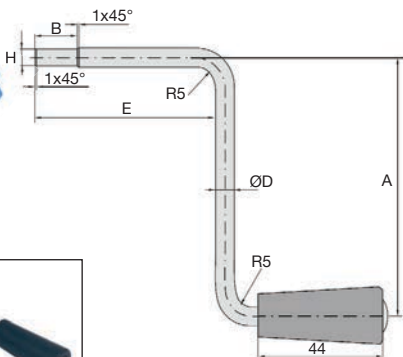

Used with a RVM14 gearbox

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 10+ | 25+ | 50+ |
| Disc. | List | -5% | -15% | On request |

| Part number | A | H | ØD | E | B | Price each 1 to 9 |
|-------------|----|---------|----|----|----|----------------------|
| MBEX6-90 | 90 | hex 6mm | 7 | 60 | 20 | 57,50 € |
| MBEX7-90 | 90 | hex 7mm | 8 | 62 | 15 | 46,00 € |

Dimensions in mm

Our other products



PLA

Flat magnet, Flat magnet with thread




CAP880

Side flexing slim slat top chain acetal, Narrow range 880



SLB

Indexing plunger, stainless steel

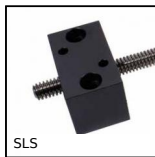

SLS

Bearing block for leadscrew, Fixed Drylin® bearing block



ACLALF

Adjustable foot for aluminium profile, Ideal for workstations



PRF_ART

Articulated bracket for use with aluminium profile, With clamping ha...



PRF_JL4

Lip seal for panel, Door seal - Ø 4mm



VML

Stainless steel hexagonal headed thumb screw, Male



PRF4545_P

Stripp Aluminium profile with extendable slot, 45 x



PCS37

Chain sprocket - steel, 9.525mm (DIN06B-1)



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



DTR

Chain idler sprocket, Chain idler sprocket - Steel

Complementary products



RAM30

Manual bevel gearbox, Bevel



RVM14

Manual worm and wheel gearbox, Worm/wheel



RAM35

Manual bevel gearbox, Bevel



RVM25

Manually operated gearbox, Bevel