

Threaded locking clamp

Sta Stock

MBF

Quick and easy mounting

- Hexagonal headed sleeve for quickly fastening a shaft
- By tightening the sleeve with a spanner, a shaft can be fixed in any required position
- Smooth bore
- Material:
303/304 stainless steel

Application


- Supporting sensors, connecting tubes when assembling small structures

Accessories

- To be used with APBC rods, NSP, NSU or NSD support clamps or NRV and NRR joints



Suitable for food industry use

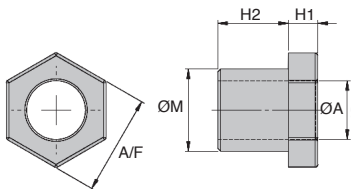

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Ext thread ØM	H1	H2	Across flat A/F	Stock*	Price each 1 to 4
MBF8-12	8	M12x1,5	5	12	15	✓	4,94 €
MBF10-14	10	M14x1,5	5	12	17	✓	5,16 €
MBF12-16	12	M16x1,5	6	12	19	✓	5,47 €

Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



MSP19

Masterplate® glueable insert Ø19, Cylindrical with tapped insert



TOC

Short swivel head, Short



WW10

Drylin® W slide, slide assembly



PRF CHA D

Hinge and joint, Lift-off hinge



CSS

Spherical bushing, Steel / self lubricating steel



CMA

Eye bolt, Steel



CCL

Standard wire thimble, Steel



CDP

Flanged drill bushing, Steel



SHA_PT

Handwheel with handle, Polyamide



PCS50

Chain sprocket - steel, 12.7mm (DIN08B-1)



VRC1

Retaining clamp, single sided, Single



WJUM10

Drylin® W bearing block, Slide

Complementary products



APBC

Circular rod, Round rod



NSP

Right angled support clamp, Right angled support clamp