

Threaded locking clamp

Sta Stock

MBF

Quick and easy mounting

- Hexagonal headed sleeve for quickly fastening a shaft
- By tightening the sleeve with a spanner, a shaft can be fixed in any required position
- Smooth bore
- Material:
303/304 stainless steel

Application


- Supporting sensors, connecting tubes when assembling small structures

Accessories

- To be used with APBC rods, NSP, NSU or NSD support clamps or NRV and NRR joints



Suitable for food industry use

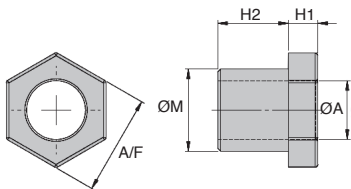

DISCOUNTS

| Qty | 1+ | 5+ | 10+ | 20+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | For rod ØA | Ext thread ØM | H1 | H2 | Across flat A/F | Stock* | Price each 1 to 4 |
|-------------|------------|------------------|----|----|--------------------|--------|----------------------|
| MBF8-12 | 8 | M12x1,5 | 5 | 12 | 15 | ✓ | 4,94 € |
| MBF10-14 | 10 | M14x1,5 | 5 | 12 | 17 | ✓ | 5,16 € |
| MBF12-16 | 12 | M16x1,5 | 6 | 12 | 19 | ✓ | 5,47 € |

Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



RHT

High Temperature wheel, up to 200kg



CLSCLP

Clevis components, short version, Steel - short range



PRS50

Stainless steel articulated foot Ø50, Ø 50



HTD8M_20

HTD Heavy duty timing pulley, HTD8 Cast



 
SBF

Open flange bearing unit for food industry, cover



LC

Friction clutch, 190 to 1800 Nm



TBV

Manual lifting tables, 7kg



YG4

HEAVY DUTY spur gear, Steel 35NCD6



PCLA_M

Technopolymer clamping lever -



PMC150_M16

Anti-vibration machine mount,



AXTR

Axle for tensioner pulley, Shaft



Q7

Angular contact ball bearing, Steel

Complementary products



APBC

Circular rod, Round rod



NSP

Right angled support clamp, Right angled support clamp